


Data sheet

2071.2 TW 1,5-4 BG

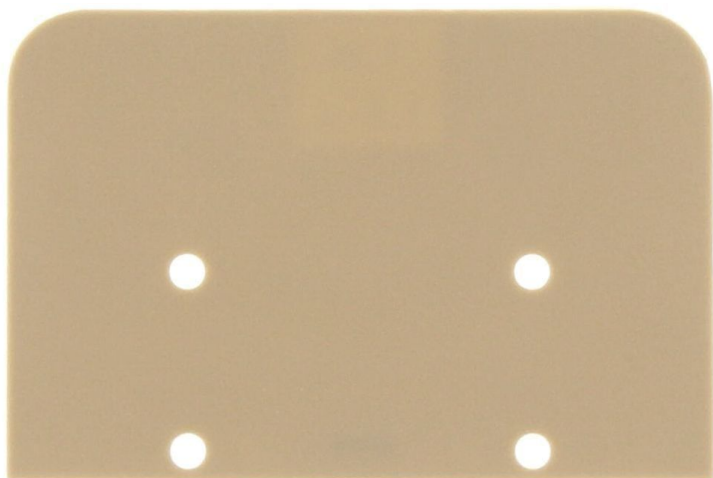

Partition plate, Width: 1.5 mm, Colour: Beige

Business data

Article number	<u>2071.2</u>
Article name	TW 1,5-4 BG
GTIN (EAN)	4044211048792
Packaging unit	50
Quantity unit	PC
Weight per piece (not including packaging)	1.1 g
Weight per piece (including packaging)	1.11 g
Unit of weight	G
Customs number	85389099
Country of origin	DE
Prio-Article	2071.2
Product description	Partition plate

Data sheet

2071.2 TW 1,5-4 BG

Technical data

Dimensions

Length	31.5 mm
Width	1.5 mm
Min. thickness	1.5 mm
Height	47 mm

Materials

Material	Polyamide 6.6
Flammability class UL 94	V-2
Working temperature, min.	-40 °C
Working temperature, max.	105 °C

Further technical data

Designed as end plate	✓
Snap-on available	✓


Environmental Product Compliance

REACH Candidate Substance Note	No
--------------------------------	----

Media

Accessories

##INVERSE##CONTA-CONNECT

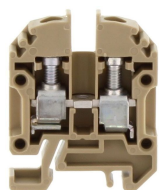


Feed-through terminal, Screw connection, Mounting type: Mounting rail TS 15/5.5, Rated cross-section: 4 mm², Width: 6 mm, Colour: Beige

Article number	Article name	GTIN (EAN)	Packaging unit
<u>1010.2</u>	RK 1,5-4/15 BG	4044211002275	100



Feed-through terminal, Screw connection, Mounting type: Mounting rail TS 35/7.5 and TS 32, Rated cross-section: 2.5 mm², Width: 5 mm, Colour: Beige

Article number	Article name	GTIN (EAN)	Packaging unit
<u>1030.2</u>	SRK 2,5 BG	4044211006723	100

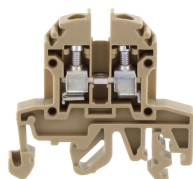

Feed-through terminal, Screw connection, Mounting type: Mounting rail TS 35/7.5 and TS 32, Rated cross-section: 4 mm², Width: 6 mm, Colour: Beige

Article number	Article name	GTIN (EAN)	Packaging unit
<u>1015.2</u>	RK 1,5-4 BG	4044211003425	100



Ex feed-through terminal ATEX-certified, Screw connection, Mounting type: Mounting rail TS 15/5.5, Rated cross-section: 4 mm², Width: 6 mm, Colour: Beige

Article number	Article name	GTIN (EAN)	Packaging unit
<u>1433.2</u>	RK 1,5-4/15 Ex BG	4044211044817	100