

End plate, Width: 1.5 mm, Colour: Beige

Business data

Article number	<u>2586.2</u>
Article name	APG 4 BG
GTIN (EAN)	4044211049089
Packaging unit	20
Quantity unit	PC
Weight per piece (not including packaging)	3.2 g
Weight per piece (including packaging)	3.32 g
Unit of weight	G
Customs number	85389099
Country of origin	DE
Prio-Article	2586.2
Product description	End plate

Data sheet

2586.2 APG 4 BG

Technical data

Dimensions

Length	57.4 mm
Width	1.5 mm
Min. thickness	1.5 mm
Height	52.7 mm

Materials

Material	Polyamide 6.6
Flammability class UL 94	V-2
Working temperature, min.	-40 °C
Working temperature, max.	105 °C

Further technical data

Designed as end plate	✓
Snap-on available	✓

Environmental Product Compliance

REACH Candidate Substance Note	No
--------------------------------	----

Data sheet


2586.2 APG 4 BG



Media


Accessories

##INVERSE##CONTA-CONNECT

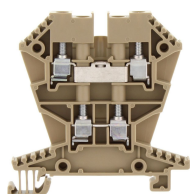


Double-level terminal, Screw connection, Mounting type: Mounting rail TS 35/7.5, Rated cross-section: 4 mm², Width: 6 mm, Colour: Beige

Article number	Article name	GTIN (EAN)	Packaging unit
<u>2584.2</u>	RKDG 4 BG	4044211080532	100

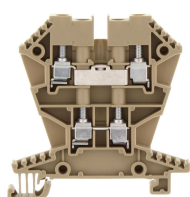

Ex double-level terminal ATEX-certified, Screw connection, Mounting type: Mounting rail TS 35/7.5 and TS 32, Rated cross-section: 4 mm², Width: 6 mm, Colour: Beige


Article number	Article name	GTIN (EAN)	Packaging unit
<u>1496.2</u>	RKDG 4 Ex BG	4044211107925	100

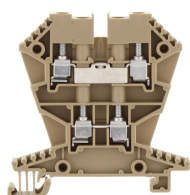

Double-level terminal, Screw connection, Mounting type: Mounting rail TS 35/7.5, Rated cross-section: 4 mm², Width: 6 mm, Colour: Beige

Article number	Article name	GTIN (EAN)	Packaging unit
<u>2584.2</u>	RKDG 4 BG	4044211080532	100

##INVERSE##CONTA-CONNECT

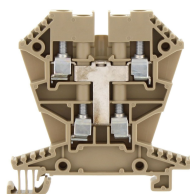

Double-level terminal, Screw connection, Mounting type: Mounting rail TS 35/7.5, Rated cross-section: 4 mm², Width: 6 mm, Colour: Beige

Article number	Article name	GTIN (EAN)	Packaging unit
<u>17048.2</u>	RKDG 4/SV BG	4044211155889	100