



TO-263-3 to DIP-6 SMT Adapter (100 mils pitch, 400 x 390 mils body)

REF.	DIMENSIONS					
	mm			inches		
	MIN.	TYP.	MAX.	MIN.	TYP.	MAX.
A		3.20				
B		4.00				
C		1.75				
B2		10.00				
C2		11.00				
D		0.79				
E		2.54				
F					0.600	
G					0.100	
H					0.025	

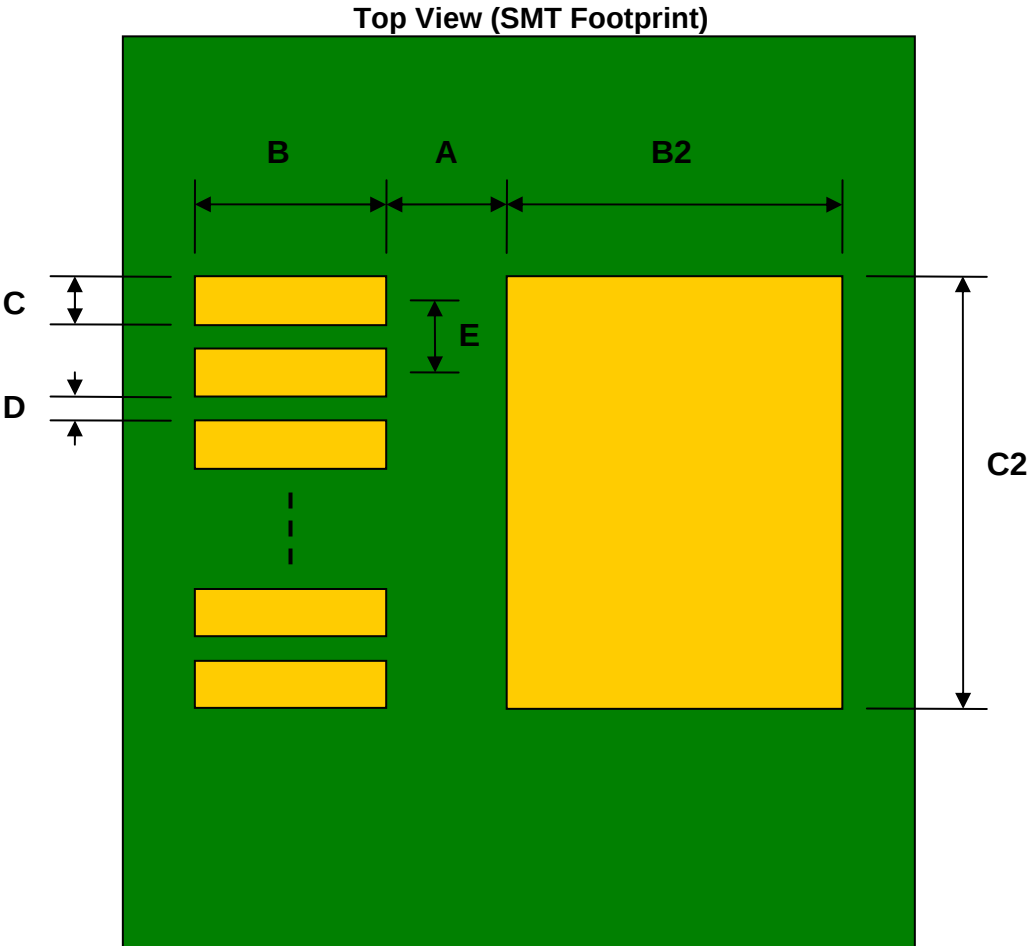


(Representative drawing only - not to scale)

Bottom View (DIP Pins)

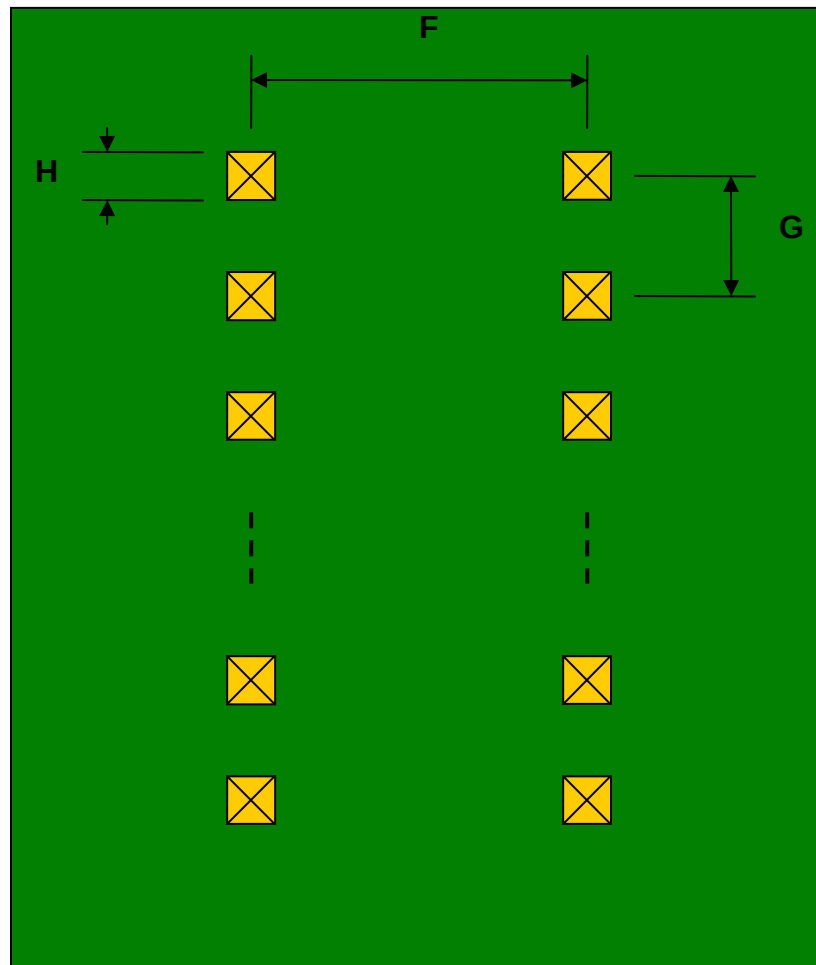

(Representative drawing only - not to scale)

Side View (DIP Pins)

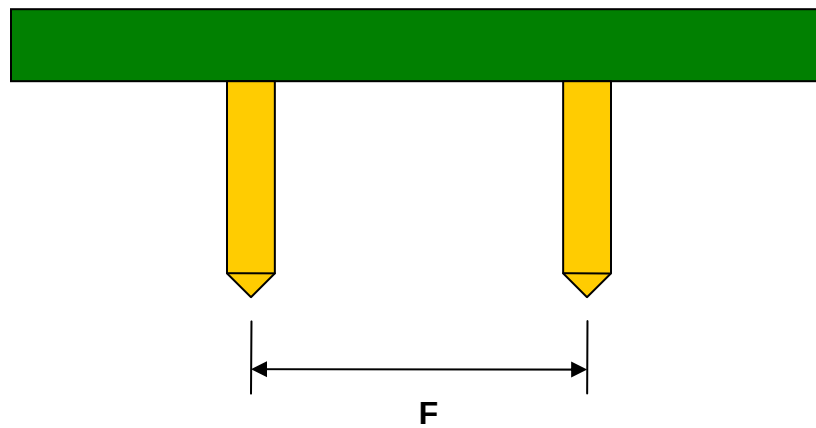

(Representative drawing only - not to scale)