 
 
 
 

 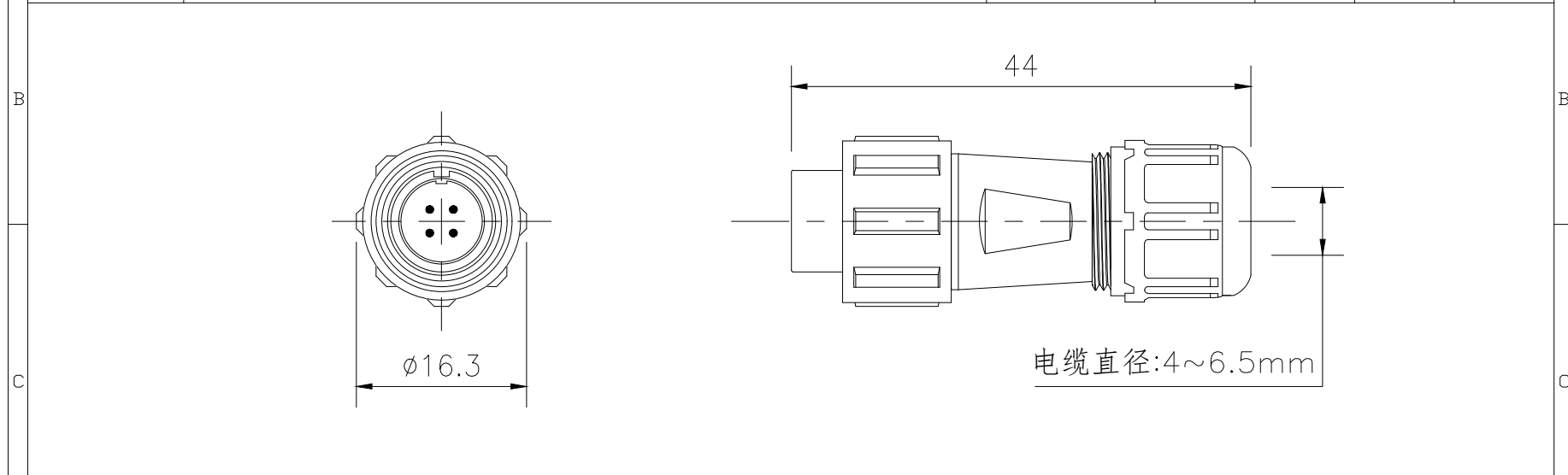


芯位	2	3	4	5	6				
	 2P	 3P	 4P	 5P	芯数	2P	3P	4P	5P
					工作电压 (V)	180	180	125	125
					额定电流 (A)	5	5	3	3
					耐压 (V)	1000	1000	1000	1000
				接触电阻 (mΩ)	5	5	10	10	



材料和技术参数

接插方式:	螺纹锁紧
外壳材料:	热塑性塑料PC, PA66 防火等级: V-0
绝缘体:	热塑性塑料PPS, 耐高温260° C
接触件材料:	铜, 镀金
电缆直径:	4-6.5 mm
防护等级:	IP68
接插次数:	500
温度范围:	-40°C ~ +85°C
绝缘电阻:	2000 MΩ

GENERAL TOLERANCE (UNLESS SPECIFIED)	DWN	DATE	TITLE JH1110P 塑料组装式针型插头
	L.L	2022.10.10	
≤10 ±0.1	CHK	DATE	PART NO
<10~≤20 ±0.2	APVD	DATE	
<20~≤50 ±0.5	UNIT	REV	DRAWING NO
Angle ±1°	MM	A	
 THIRD ANGLE	SIZE	SHEET	1 OF 1
	A4		