
 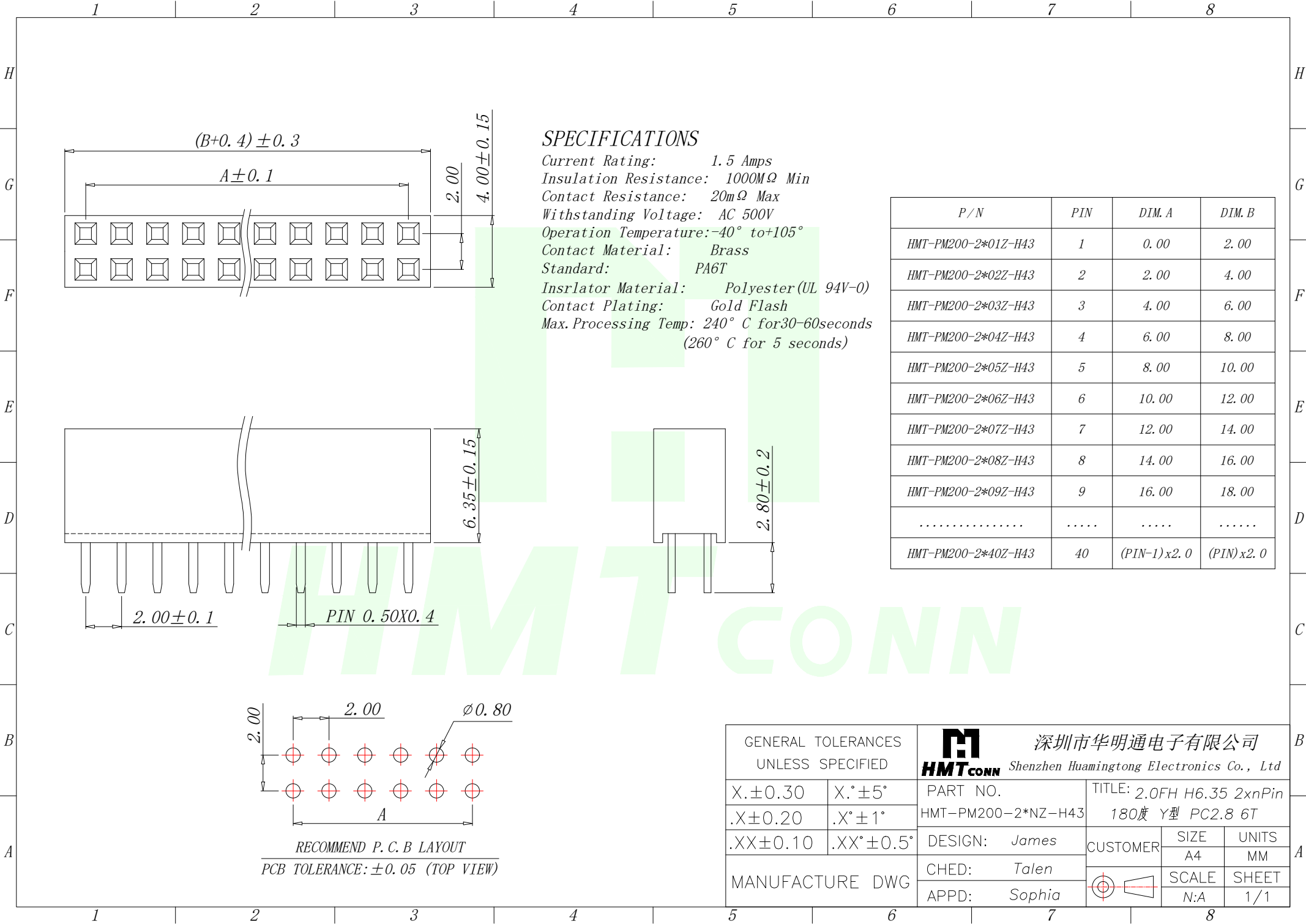




SPECIFICATIONS

Current Rating: 1.5 Amps
Insulation Resistance: 1000M Ω Min
Contact Resistance: 20m Ω Max
Withstanding Voltage: AC 500V
Operation Temperature: -40° to +105°
Contact Material: Brass
Standard: PA6T
Insrlator Material: Polyester (UL 94V-0)
Contact Plating: Gold Flash
Max. Processing Temp: 240° C for 30-60 seconds
(260° C for 5 seconds)

P / N	PIN	DIM. A	DIM. B
HMT-PM200-2*01Z-H43	1	0.00	2.00
HMT-PM200-2*02Z-H43	2	2.00	4.00
HMT-PM200-2*03Z-H43	3	4.00	6.00
HMT-PM200-2*04Z-H43	4	6.00	8.00
HMT-PM200-2*05Z-H43	5	8.00	10.00
HMT-PM200-2*06Z-H43	6	10.00	12.00
HMT-PM200-2*07Z-H43	7	12.00	14.00
HMT-PM200-2*08Z-H43	8	14.00	16.00
HMT-PM200-2*09Z-H43	9	16.00	18.00
.....			
HMT-PM200-2*40Z-H43	40	(PIN-1) x 2.0	(PIN) x 2.0

GENERAL TOLERANCES UNLESS SPECIFIED		 深圳市华明通电子有限公司 HMTconn Shenzhen Huamingtong Electronics Co., Ltd		
X. ± 0.30	X.° $\pm 5^\circ$	PART NO.	TITLE: 2.0FH H6.35 2xnPin	
.X ± 0.20	.X° $\pm 1^\circ$	HMT-PM200-2*NZ-H43	180度 Y型 PC2.8 6T	
.XX ± 0.10	.XX° $\pm 0.5^\circ$	DESIGN: James	CUSTOMER	SIZE
MANUFACTURE DWG		CHED: Talen		UNITS
		APPD: Sophia		SCALE
				SHEET
				N:A
				1/1