

产品名称 Product name

▶ 2.54PH H2.5 2**n*Pin 90度
▶ PC3.0 PA6.0 PB6.9
L13.8/18.8 弯凹面

产品应用场景 Product application scenario

- ▶ 电子通讯/数码产品/家用电器
- ▶ 外围设备/汽车/医疗设备等.
- ▶ Electronic communication/digital products/household appliance peripherals/AuTomobile/medical equipment, etc

排针系列™
Needle arrangement series™

产品参数/Product parameters

额定电流 (Rated current): 3A AC/DC

盐雾实验 (Life Test): 24 hours

接触电阻 (Contact Resistance): 20mΩ

绝缘电阻 (Insulation Resistance): 1000MΩ min.

耐电压 (Withstand voltage): AC 1000V

工作温度 (Operating Temperature): -40° C to 105°

防火等级 (Fire rating): Polyester (UL94V-0)

触点电镀 (Dielectric Strength): Gold Flash

耐高温范围/时长 (High temperature resistance range/duration): 260° C for 5seconds

包装方式 (Packaging method): 袋装

材质/MATERIALS:

No.	名称/NAME	材料/MATERIAL	表面处理/颜色 Surfacetreatment/color
①	端子/Terminal	Brass/C2680	镀金 gold-plating
②	塑胶/plastic cement	PBT/PA6T	黑色 Black

产品PIN位示意图/Schematic diagram of product PIN

No. of	DIM. A	DIM. B	No. of	DIM. A	DIM. B	No. of	DIM. A	DIM. B	No. of	DIM. A	DIM. B
2*1P	0.00	2.54	2*11P	25.40	27.94	2*21P	50.80	53.34	2*31P	76.20	78.74
2*2P	2.54	5.08	2*12P	27.94	30.48	2*22P	53.34	55.88	2*32P	78.74	81.28
2*3P	5.08	7.62	2*13P	30.48	33.02	2*23P	55.88	58.42	2*33P	81.28	83.82
2*4P	7.62	10.16	2*14P	33.02	35.56	2*24P	58.42	60.96	2*34P	83.82	86.36
2*5P	10.16	12.70	2*15P	35.56	38.10	2*25P	60.96	63.50	2*35P	86.36	88.90
2*6P	12.70	15.24	2*16P	38.10	40.64	2*26P	63.50	66.04	2*36P	88.90	91.44
2*7P	15.24	17.78	2*17P	40.64	43.18	2*27P	66.04	68.58	2*37P	91.44	93.98
2*8P	17.78	20.32	2*18P	43.18	45.72	2*28P	68.58	71.12	2*38P	93.98	96.52
2*9P	20.32	22.86	2*19P	45.72	48.26	2*29P	71.12	73.66	2*39P	96.52	99.06
2*10P	22.86	25.40	2*20P	48.26	50.80	2*30P	73.66	76.20	2*40P	99.06	101.60

产品编号/Product No



1: 产品类别/Product Category

PH: 排针
FH: 排母

2: 产品流水号/Product Serial Number

16: 双排弯凹面

3: 产品间距/product spacing

127-1.27mm
200-2.00mm
254-2.54mm

4: 产品PIN位/Product PIN position

22P-2*2P

5: 上针长度/upper needle length

C60: 6.0mm

6: 下针长度/needle penetration depth

D30: 3.0mm

7: 塑胶高度/plastic height

G1-1.0 G2-1.5
G3-2.0 G4-2.54

8: 包装方式/packaging method

P-袋装/PE B-盒装/BOX
T-管装/Tubing W-卷带/winding

9: 电镀规格/plating specifications

T0: GF T1: 1U
T3: 3U T5: 5U


致力于连接器国产化

树立智能产业新标杆

产品订购号示意图/Schematic diagram of product order number

Schematic diagram of product ordering part numbers:LCK-PH16-25422PC60D30-G4PT0


产品外形尺寸图/Outline dimension drawing of product

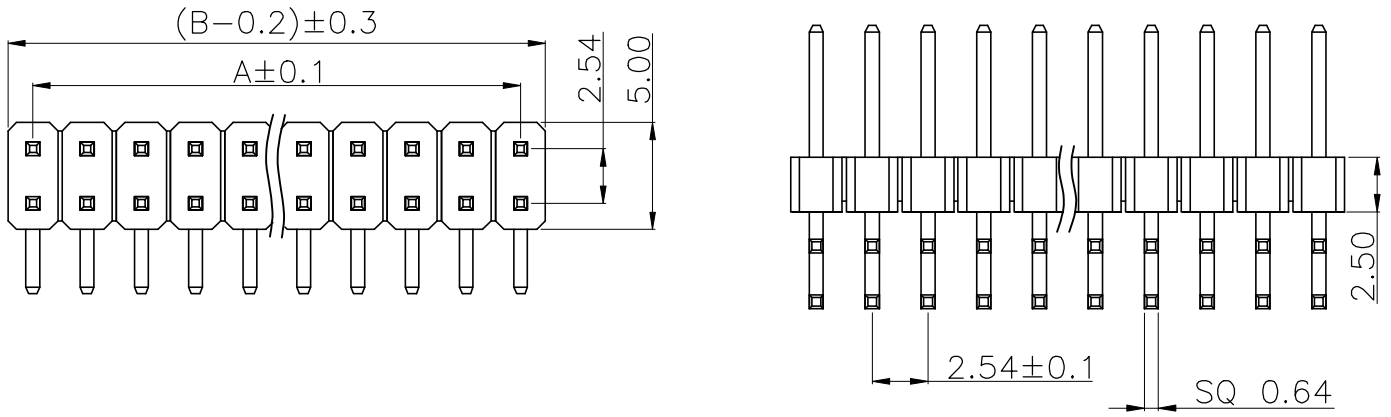


Series Needle arrangement 排针系列



致力于连接器国产化 树立智能产业新标杆

线路图/Circuit diagram


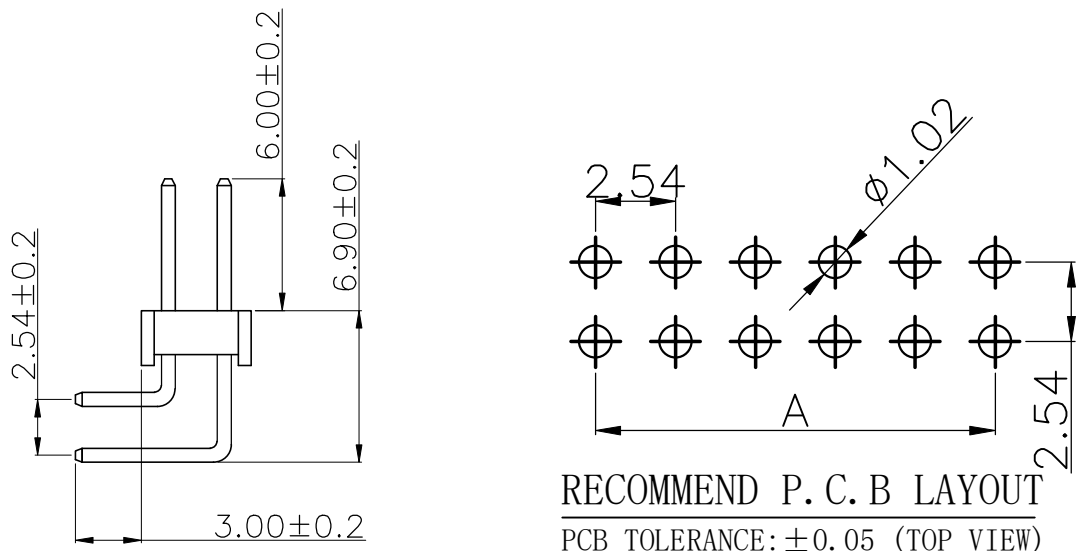


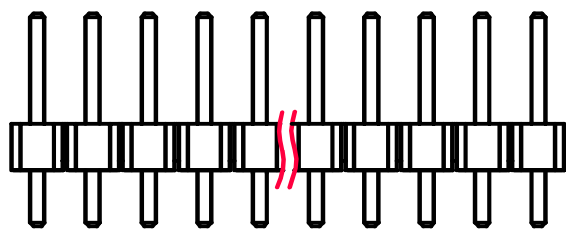

产品

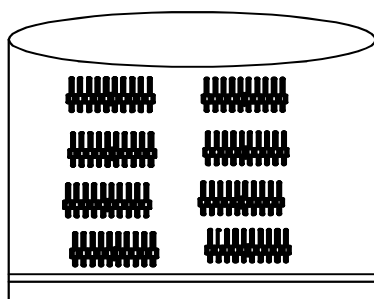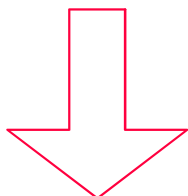

3#胶袋: 16*18cm

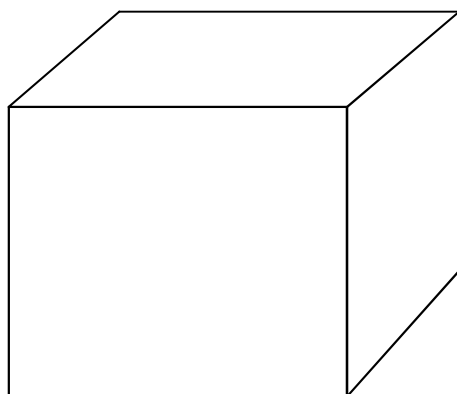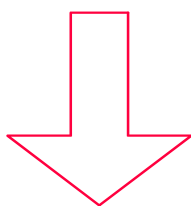

纸箱

Series Needle arrangement
排针系列

致力于连接器国产化
树立智能产业新标杆