


## Coaxial Cable Connector 16\_MM CX-50-2-4/111\_O

### Description

Right angle cable plug

Interface standards

SUHNER-MM CX

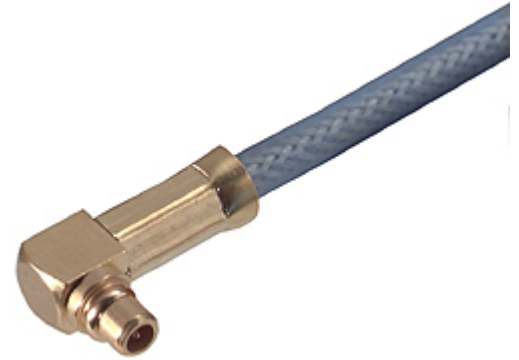

### Technical Data

#### Electrical Data

Impedance	50 $\Omega$
Interface frequency max.	6 GHz

#### Mechanical Data

Centre contact	soldered
Outer contact	crimped
Weight	0.0009 kg

#### Environmental Data

Operating temperature	-55 °C to 155 °C
2011/65/EU (RoHS - including 2015/863 and 2017/2102)	compliant

#### Material Data

Piece Parts	Material	Surface Plating
Centre contact	Copper Beryllium Alloy	Gold Plating (Nickel underplated)
Outer contact	Brass	Gold Plating (without Nickel underplating)
Body	Brass	Gold Plating (without Nickel underplating)
Insulator	PFA / PTFE	
Crimp ferrule	Copper	Gold Plating (without Nickel underplating)

### Related Documents

Outline drawing	DOU-00006003
Catalogue drawing	DOU-00006005
Assembly instruction	DOC-0000241539

### Ordering Information

Bulk 100 pcs package	16_MM CX-50-2-4/111_OH
Single package	16_MM CX-50-2-4/111_OE

### Additional Information

Suitable cables	RG_316_/U, ENVIROFLEX_316, RG_188_A/U, RG_174_/U
-----------------	--