


YX-A11-R430848-RT0850



APPLICATIONS

- Cross outlet
- Coil attached square diskette, size: 43mm
- Double-sided magnetic tape
- Attach the coil to double-sided tape
- Double line tinning

SHAPE & DIMENSIONS

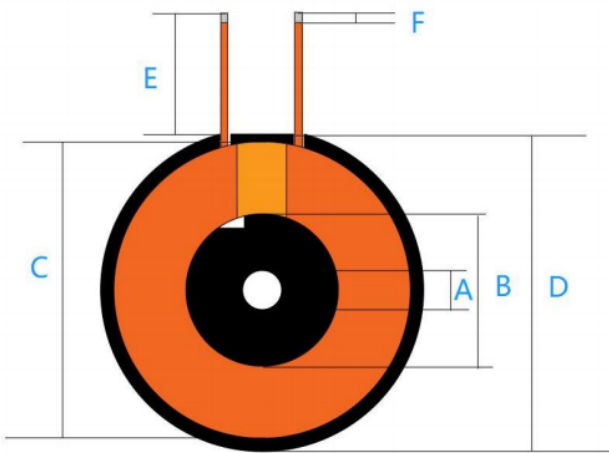

A	5.3±0.2
B	18.5±2.5
C	38.5±1.5
D	43±2
E	50±2.5
F	2±0.5
G	总厚度 1.8±0.2
H	磁片厚 0.8±0.1



AIR COIL SPECIFICATIONS

Number of Coils	Wire Diameters	Turns Ratio
1	∅:0.08*24*2P	2P*10TS

MAXIMUM RATINGS

Operating Temperature / Humidity	Storage Temperature / Humidity
-40 to +85°C / 10 to 65% R.H.	-25 to +125°C / 10 to 65% R.H.

ELECTRICAL CHARACTERISTICS

OCL [100kHz 0.1V] (μH)	DCR [100kHz 0.1V] (mΩ)	WPC Compliant
6.50 ± 10%	70max.	Yes

PACKAGING : BOX TYPE

Dimensions (mm)		Quantity (pcs)	
Tray	—	Qty per tray	—
Small carton	320x320x55	Qty per small carton	6
Outer carton	350x350x180	Qty per outer carton	300

OTHERS

Weight (g) typ.	32.90
-----------------	-------