


客户图

NO.	ECN NO.	DESCRIPTION	DATE

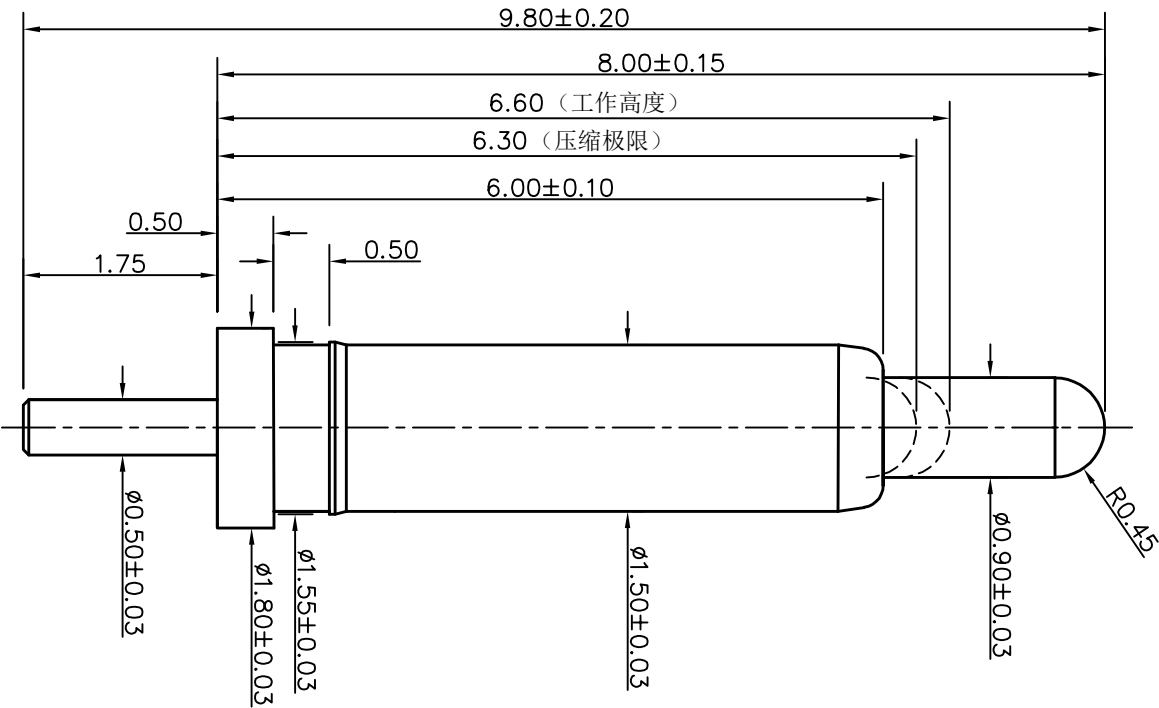

Note:

- 1: Material (材料) :
 Barrel: Brass C3604 (针管: 黄铜 C3604)
 Plunger: Brass C3604 (针头: 黄铜 C3604)
 Spring: SUS304 (弹簧: SUS304)
- 2: Plating (电镀) :
 Barrel: 5u' Au over 50~80u' Ni (针管: 镀金5u', 镍底50~80u'.)
 Plunger: 5u' Au over 50~80u' Ni (针头: 镀金5u', 镍底50~80u'.)
- 3: Electrical (电气特性) :
 Rated Current & Voltage: DC 12V;3A (额定电压&电流: 直流12V,3A)
 Contact Resistance: 50 mohm Max. at working height.
 接触电阻: 最大50毫欧 (在工作高度状态下)
- 4: Mechanical (机械性能) :
 Force: 120g±20% at working height. (120g±20%在工作高度)。
 Durability: 10.000 cycles(min) (寿命: 10000次)
- 5: Work Temperature (工作环境):
 Withstanding Higt Temperature: 280t
 Operational Temperature: -40t~ +85t

深圳市鑫探技术有限公司

HTTP://WWW.XYZPOGOPIN.COM
 TEL: 0755-28773277 FAX: 0755-28891353



SCALE:	N/A	UNIT	mm
SHEET:	1 of 1	PROJECTION	⊕
DATE:	2026.04.21	VER.	D.0

THE UNMARKED TOLERANCE ARE AS BELOW :

LENGTH	ANGLE
XXX ±0.05mm	X.XX ±0.50°
XX ±0.10mm	X.X ±1.00°
X ±0.20mm	X. ±2.00°

DESIGNED BY:	DWG. NO.	YZ186215098P-01
CHECKED BY:	TITLE:	Pogo pin连接器
APPROVED BY:		