

 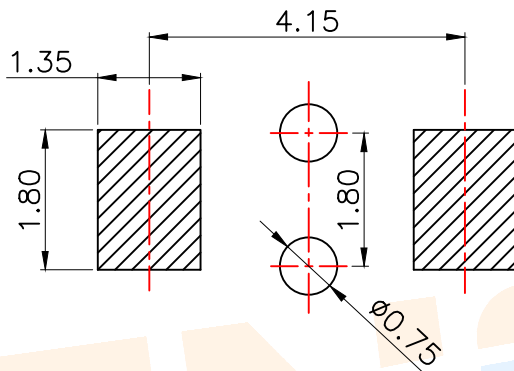



RoHS

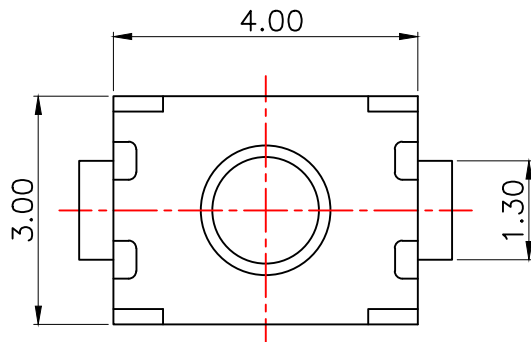



PCB Layout(Pattern side)



Circuit Diagram

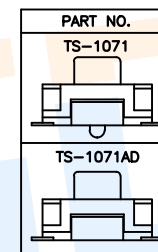

TOTAL HEIGHT	
Code	H
020	2.0
025	2.5
030	3.0
035	3.5
038	3.8
040	4.0
050	5.0

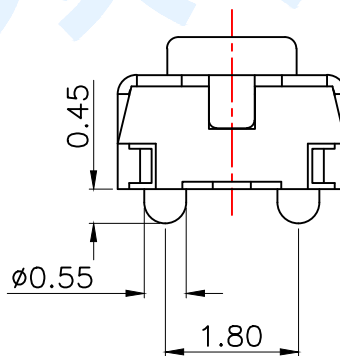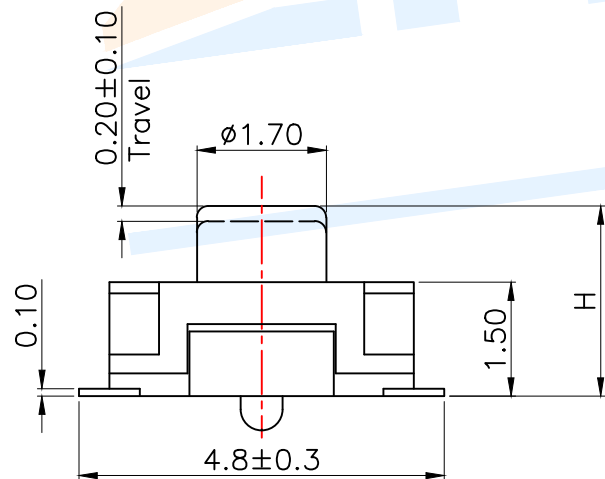

Product No. : TS-071-□□-□□

型号:

产品高度 (H) :

020=2.0mm

025=2.5mm

030=3.0mm

包装方式

-P=编带 (非编带, 不启用)

弹片

D2=SUS/1PCS

D4=SUS/2PCS

操作力度:

120=120gf±50gf

180=180gf±50gf

250=250gf±50gf

Ⓕ	Dust film		1	Polyimide tape	
Ⓔ	Terminal		2	Phosphorus bronze	Silvering
Ⓓ	Reed		2	SUS	Silver Covered
Ⓒ	Button		1	LCP	Black
Ⓑ	Cover		1	SUS	Natural
Ⓐ	Base		1	LCP	Black
NO.	Name	Number	Qty	Materil	Remarks

ZHONGDI
众迪

Zhongdi Electronic Technology Co., Ltd

design	date	name	TACT SWITCHS
Review	date	model	TS-071-□□-D□
Approved	date		

Drawing number:

modify Review Approved Tolerance not specified Proportion 1:1 unit mm gage number A4

项 目 Item	技术参数 Technical Parameter	标 准 Standard
电气性能 Electrical Properties	额定电流 Rated Current:	50mA
	额定电压 Rated voltage:	DC 12V
	接触电阻 Contact resistance:	≤100mΩ
	绝缘电阻 Insulation Resistance:	DC 250V 1 min ≥100MΩ
机械性能 Mechanical Properties	耐压强度 Compressive strength:	AC 250V 50Hz/1 min
	机械寿命 Mechanical life:	100,000 cycles Min
环境性能 Environmental	操作行程 Operation Stroke:	0.20±0.10mm
	工作温度 Operation temperature:	-25℃~ +75℃
可靠性特性 Reliability Characteristics	使用湿度 Use humidity:	≤85% RH
	回流焊 Reflow Soldering:	≤260℃ 时间 Time 3s
	波峰焊 Wave soldering:	
应用领域 Application area	手工焊 Manual welding:	≥260℃ 时间 Time 3s
	影音产品、电子玩具、数码产品、通讯产品、安防产品等。 Audiovisual products, electronic toys, digital products, communication products, security products, etc	



绝缘电阻测量仪



直流低电阻测试仪




耐电压测试仪



回流焊机



二次元测量仪

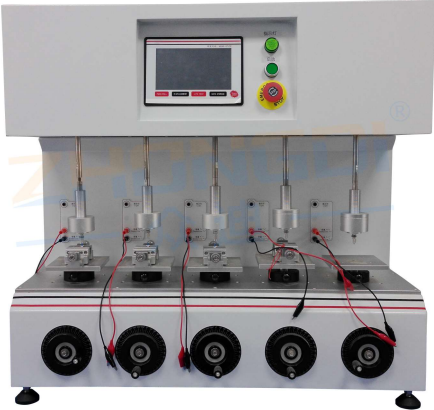

高精密寿命测试仪



盐雾测试仪



按键荷重曲线仪

ZHONGDI® 众迪												Zhongdi Electronic Technology Co., Ltd													
design			date			name			TACT SWITCHS																
Review			date			name			TS-071-□□-D□																
Approved			date			name			TS-071-□□-D□																
umber:																									
1:1			unit			mm			gape number			A4													