

Actuator

45-
280X.2D90.003



<https://eao.com/p/45-280X.2D90.003>

Your product:



45-280X.2D90.003 Actuator

FRONT

Front dimension:	Ø 29,5 mm
Front bezel colour:	Silver
Front bezel material:	Metal

MOUNTING

Design:	raised
----------------	--------

OPERATING-/INDICATION PART

Lever colour:	White
Lever shape:	long
Lever material:	plastic

MECHANICAL CHARACTERISTIC

Weight:	0.053 kg
Switching action:	Momentary - Rest - Maintained
Switching positions:	3 positions
Switching angle:	45° left / 45° right / -45° ... +45°
Mechanical lifetime:	1 Mio. cycles of operation
Operating frequency:	1 800/h

AMBIENT CONDITION

IP front protection:	IP66, IP67, IP69K
-----------------------------	-------------------

Operating temperature: – 25 °C ... + 70 °C

Storage temperature: – 40 °C ... + 80 °C

Climate resistance: During operation according to IEC 60721: 3K6, 3C3, 3S2, 3M6

Vibration resistance: According to IEC 60068-2-6: 10 ... 500 Hz: 5 g

Shock resistance: According to IEC 60068-2-27: Sinusoidal half-wave 50 g / 11 ms


OTHER

Housing material: Metal


Hints: External diameter of the long lever 44.8 mm

Short Description: Actuator, Ø 29,5 mm, optional illuminative, White, long, Silver, Metal, Momentary - Rest - Maintained, IP66, IP67, IP69K


Dimension drawings:

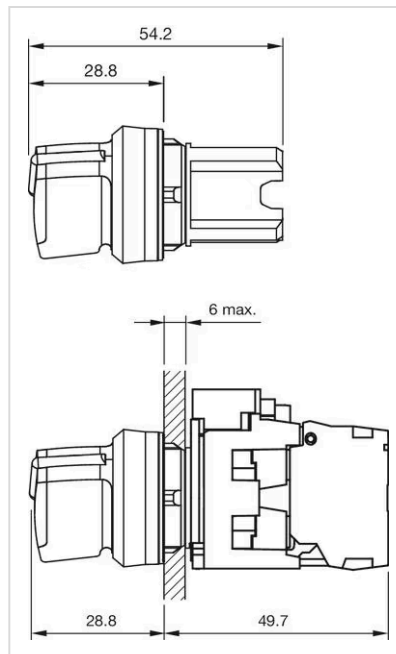

Mounting cut-outs:

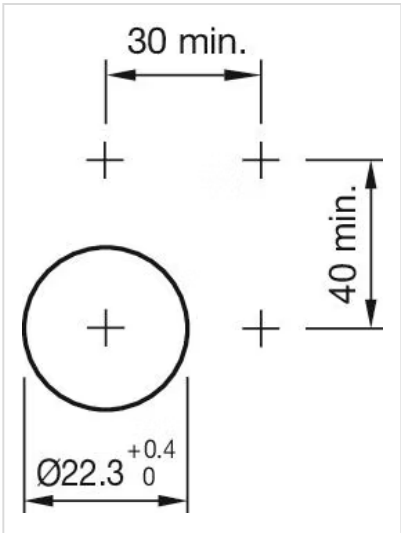

Switching positions:

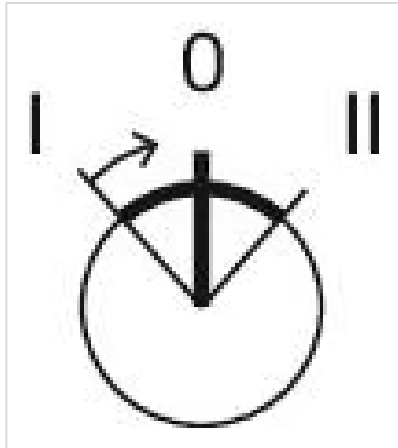

Wiring diagrams:

