
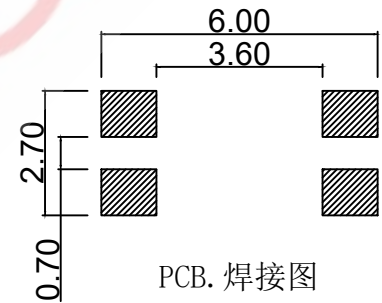
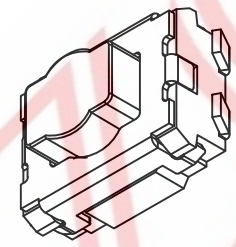
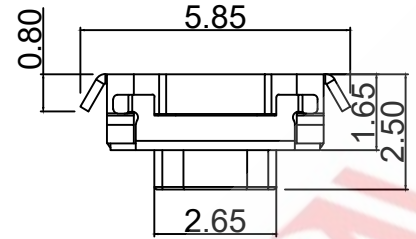
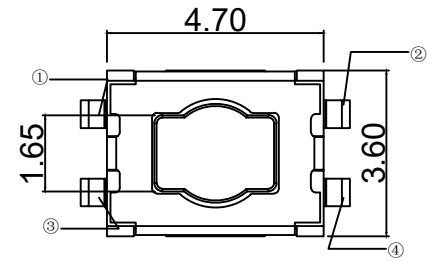


SAMZO REAC/ROHS

REV	ECN NO	DESCRIPTION	DESIGN	APPROVAL	DATE
A1	NEW	Replace frame			2018.06.12

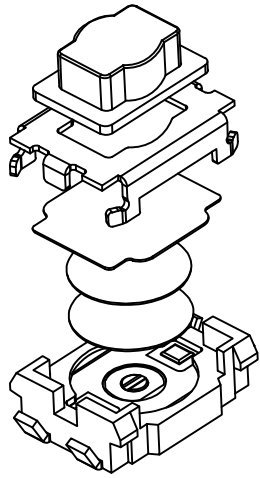



CS 4 E 25 1 1 1 0
 A B C D E F G H

- A. 系列:CS-3.5*4.7mm
- B. 贴装方式:4-立式贴片
- C. 引脚规格:E-4PIN
- D. 操作高度:25-2.5mm
- E. 操作力度:1-180gf
- F. 操作寿命:1-500,000/次
- G. 固定方式:1-无住
- H. 物料编码:0-常规

主要技术参数、性能

The Main Thchnology Performance

额定电流、电压 Rate voltage, current	50mA DC12V
接触电阻 Contact resistance	≤50mΩ
按力 Operating force	±40gf
行程 Travel	0.20±0.10mm
绝缘电阻 Insulated resistance	≥100MΩ
介电强度 Dielectric strength	≥250VAC/1min

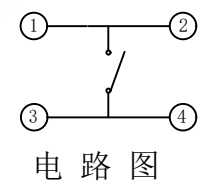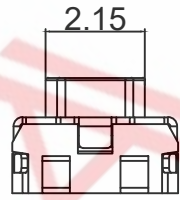

序号	零件名称	材料规格	数量	备注
6	引脚、触点	黄铜	1	镀银
5	基座	LCP	1	耐温280℃ (黑色)
4	防尘膜	PI	1	耐温280℃ (黄色)
3	簧片	不锈钢	2	覆银
2	盖板	不锈钢	1	/
1	按钮	PPA&硅胶	1	耐温280℃ (黑色)

DESIGN	WANGUIFA	2018.06.12	≥0~2<	±0.15
CHECKED	ZHENGUILAN	2018.06.12	≥2~5<	±0.25
APPROVED	LILIANJIANG	2018.06.14	≥0~2<	±0.15
			≥5	±0.35

FIRST VIEW

SCALE 1:1 UNIT mm

SAMZO COMPONENTS
Electronic switch and connector manufacturer

The copyright belongs to samzo parts [China] Co., Ltd. please use the material after samzo parts agree to authorize. The final right of interpretation belongs to samzo parts. WWW.KKK-JP.COM

TITLE: 3.5*4.7*2.5 梅花柄 U型脚

DWG NO: CS4E-P113

PART NO: CS4E150025

MODEL NO: CS4E251110

NAME: TACT SWITCH

