



Cable Assemblies > Copper Cable Assemblies > Internal I/O Cable Assemblies



Cable Assembly Type: **Sliver Pigtail**
Connector Type (End A): **Sliver Plug**
Cable Assembly Category: **High Speed**
Number of Positions: **74**
Number of Power Positions: **0**

Features

Product Type Features

Cable Assembly Type	Sliver Pigtail
Connector Type (End A)	Sliver Plug
Cable Assembly Category	High Speed

Configuration Features

Number of Positions	74
Number of Power Positions	0
Number of Signal Positions	74

Body Features

Cable Flammability Rating	UL 94V-2
---------------------------	----------

Dimensions

Wire Size	33 AWG
-----------	--------

Operation/Application

Halogen Free	No
--------------	----



Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2023 (235) Candidate List Declared Against: JUNE 2023 (235) Does not contain REACH SVHC
Halogen Content	Not Low Halogen - contains Br or Cl > 900 ppm.
Solder Process Capability	Not reviewed for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts


TE Part # 2292069-1
RCPT ASSEMBLY SMT RA 74 POSN
MBC

TE Part # 2291316-1
RCPT CONN VERTICAL 74 POSN
SLIVER


TE Part # 2291316-2
RCPT CONN VERTICAL 74 POSN
SLIVER

Also in the Series | Sliver for SFF-TA-1002



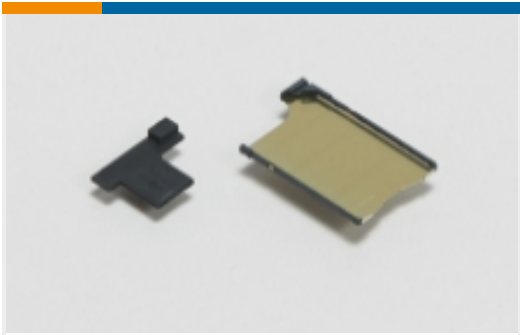

Card Guide Hardware(1)

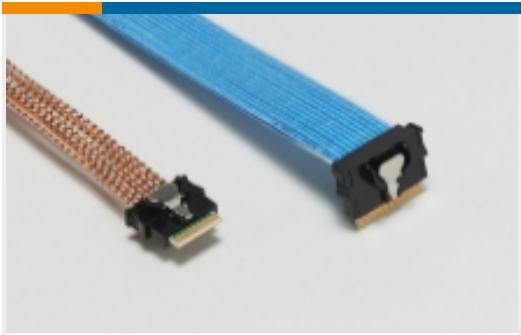

Internal I/O Cable Assemblies(109)



Internal I/O Connectors(135)

Customers Also Bought



TE Part #640456-5
05P MTA100 HDR ASSY F/L SQ STR



TE Part #3-643813-5
05P MTA100 CONN ASSY POL RIB



TE Part #104482-3
08 SHORT PT RCPT HSG DR .100CL



TE Part #54775-1
TERMINAL,PG R 16-14 6-8-10



TE Part #2294415-1
INDUSTRIAL MINI I/O HDR TYPE I TRAY



 
TE Part #2821385-1
SLIVER C/A, 74P, R/A TO R/A, 10GHZ, 85OHM




TE Part #5531216-1
CONT.TDM.SPRING STRIP



TE Part #1-1600238-2
STR W/KEYS,MBXL,2P+48S+2P



 TE Part #1761386-3
CONT PLUG 12-14AWG MULTI BEAM



TE Part #3-1600788-6
SQUEEZE REL RECEPT ASSY W/KEYS 2P+48S+2P

Documents

Product Drawings
CABLE PLUG KIT, SLIVER 74P
English

CAD Files
3D PDF
3D
Customer View Model
ENG_CVM_CVM_2317823-1_A.2d_dxf.zip



English

Customer View Model

[ENG_CVM_CVM_2317823-1_A.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_CVM_2317823-1_A.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

[Sliver Internal Cabled Interconnect Solutions Brochure \(Chinese\)](#)

Product Specifications

[Product Specification](#)

English

Product Environmental Compliance

[Product Compliance](#)

English

[Product Compliance](#)

English