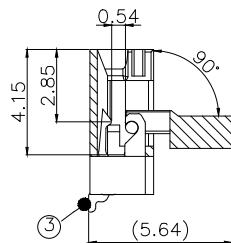
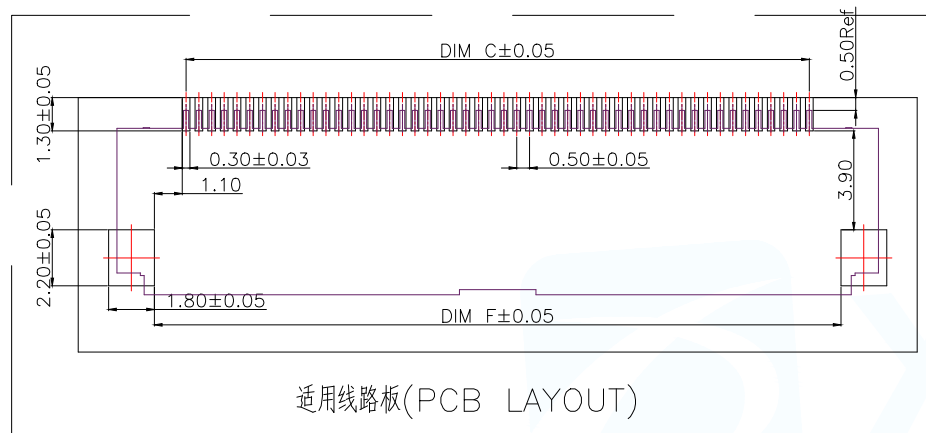





技术指标:

1. 塑件表面应光洁、无毛边、无明显收缩、缺陷、裂纹等现象。
2. 温度范围: $-25^{\circ}\text{C}\sim 85^{\circ}\text{C}$ 。
3. 额定电流: 0.5A
4. 额定电压: 50V, AC.
5. 接触电阻: 50m Ω MAX.
6. 绝缘电阻: 500M Ω Min.
7. 耐电压: 150V AC/1Minute

 
SECTION A-A
SCALE 1:1

适用线路板(PCB LAYOUT)

P/N	PIN	DIM A	DIM B	DIM C	DIM D	DIM E	DIM F
FPC-0.5FXS-5PWBR-H255	5	7.45	3.07	2.00	7.10	4.60	4.50
FPC-0.5FXS-6PWBR-H255	6	7.95	3.57	2.50	7.60	5.10	5.00
FPC-0.5FXS-7PWBR-H255	7	8.45	4.07	3.00	8.10	5.60	5.50
FPC-0.5FXS-8PWBR-H255	8	8.95	4.57	3.50	8.60	6.10	6.00
FPC-0.5FXS-9PWBR-H255	9	9.45	5.07	4.00	9.10	6.60	6.50
FPC-0.5FXS-10PWBR-H255	10	9.95	5.57	4.50	9.60	7.10	7.00
FPC-0.5FXS-11PWBR-H255	11	10.45	6.07	5.00	10.10	7.60	7.50
FPC-0.5FXS-12PWBR-H255	12	10.95	6.57	5.50	10.60	8.10	8.00
FPC-0.5FXS-13PWBR-H255	13	11.45	7.07	6.00	11.10	8.60	8.50
FPC-0.5FXS-14PWBR-H255	14	11.95	7.57	6.50	11.60	9.10	9.00
FPC-0.5FXS-15PWBR-H255	15	12.45	8.07	7.00	12.10	9.60	9.50
FPC-0.5FXS-16PWBR-H255	16	12.95	8.57	7.50	12.60	10.10	10.00
.....							
FPC-0.5FXS-76PWBR-H255	76	42.95	38.57	37.50	42.60	40.10	40.00
FPC-0.5FXS-77PWBR-H255	77	43.45	39.07	38.00	43.10	40.60	40.50
FPC-0.5FXS-78PWBR-H255	78	43.95	39.57	38.50	43.60	41.10	41.00
FPC-0.5FXS-79PWBR-H255	79	44.45	40.07	39.00	44.10	41.60	41.50
FPC-0.5FXS-80PWBR-H255	80	44.95	40.57	39.50	44.60	42.10	42.00
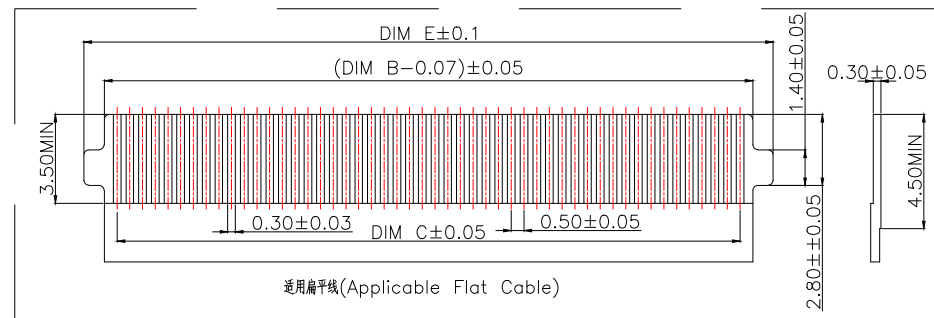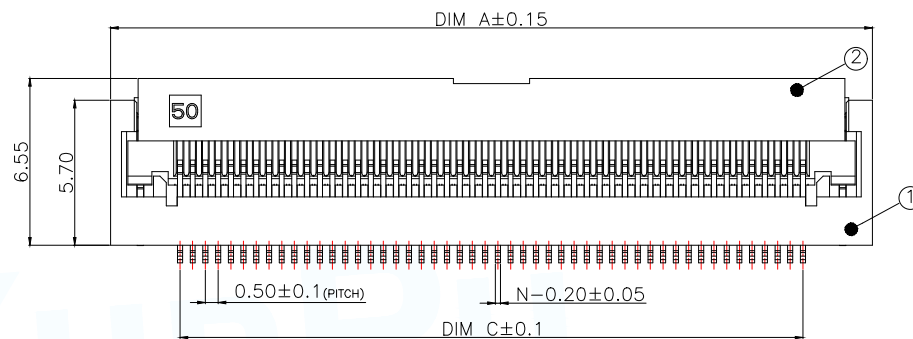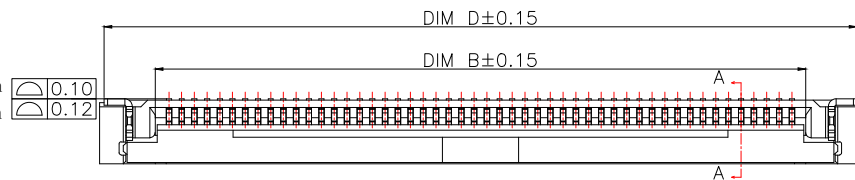
<50Pin
≥50Pin

适用扁平线(Applicable Flat Cable)



序号	品名	材质
1	0.5Pitch贴片式带扣胶壳(H=2.55)	LCP UL94V-0 本色
2	0.5Pitch贴片式后盖带扣(H=2.55)	LCP UL94V-0 黑色
3	0.5Pitch贴片式端子带扣(H=2.55)	铜合金/表面镀金
4	0.5Pitch贴片式端子带扣(H=2.55)	铜合金/表面镀锡

MANUFACTURE DWG

UNLESS OTHERWISE
SPECIFIED TOLERANCES

DECIMALS:

ANGLES:

X.:±0.50

±1°

.X.:±0.20

.XX:±0.10

.XXX:±0.05

东莞市讯普电子科技有限公司
DongGuan XunPu Electronics Co.,Ltd

TITLE:

0.5 Pitch 贴片式下接带扣(H=2.55)

PAR

FPC-0.5FXS-NPWBR-H255

DWN

Lucas

CHKD

Ethan

APVD

Jacob

SCALE 1:1

UNIT:MM

SIZE:A4

SHEET:1F1

REV:A