


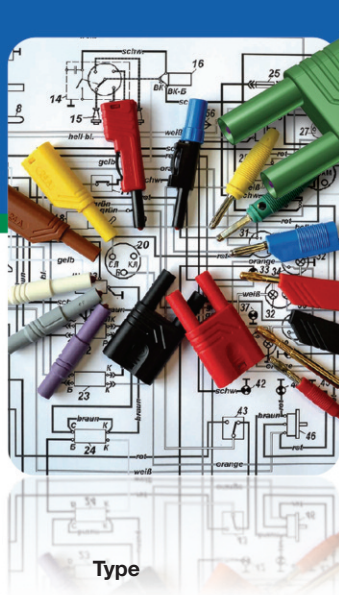

Test Plugs 2 mm System



CE

Type

MZS 2

Shrouded Adapter 2mm plug to 4mm jack.

MST S WS 30 AU

2mm safety plug, spring loaded pin, gold plated, solder terminal 0.5mm2-1.0mm2, 1000V system.

Pin diameter

2 mm (0.078")

PART NO. / Housing color

● 973600100
● 973600101

2 mm (0.078")

● 975090700
● 975090701
● 975090702
● 975090703
● 975090704
● 975090705
● 975090706
● 975090707
● 975090709

Technical Data

Contact Type	stationary
Connection Type	jack Ø4mm
Voltage Rating	30 VAC / 60 VDC
Measurement Category (IEC61010)	CAT I
Current Rating*	6A
Contact Resistance	6 mOhm

Material Specifications

Plug	nickel plated brass
Contact Spring	-
Housing	PP

Environmental Conditions

Temperature range	-20 °C to +60 °C (-4 to 140°F)
-------------------	--------------------------------

Flamability Rating

Housing	UL94 HB
---------	---------

spring loaded pin
solder terminal
AC/DC 1000V
CAT III
10A
2 mOhm



gold plated copper-beryllium
gold plated brass
Polyamide

-15°C to +70°C (-5 to 158°F)

-

Drawing

Measurements are shown in millimeters.
Multiply by 0.03937 to convert to inches.

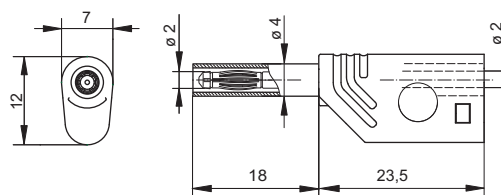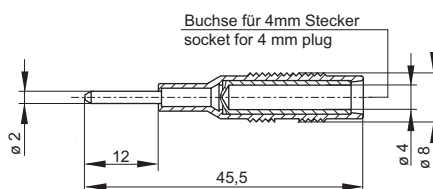

* Please consider derating graph on page 80.