


NO.	ECN NO.	DESCRIPTION	DATE
1			

客户图

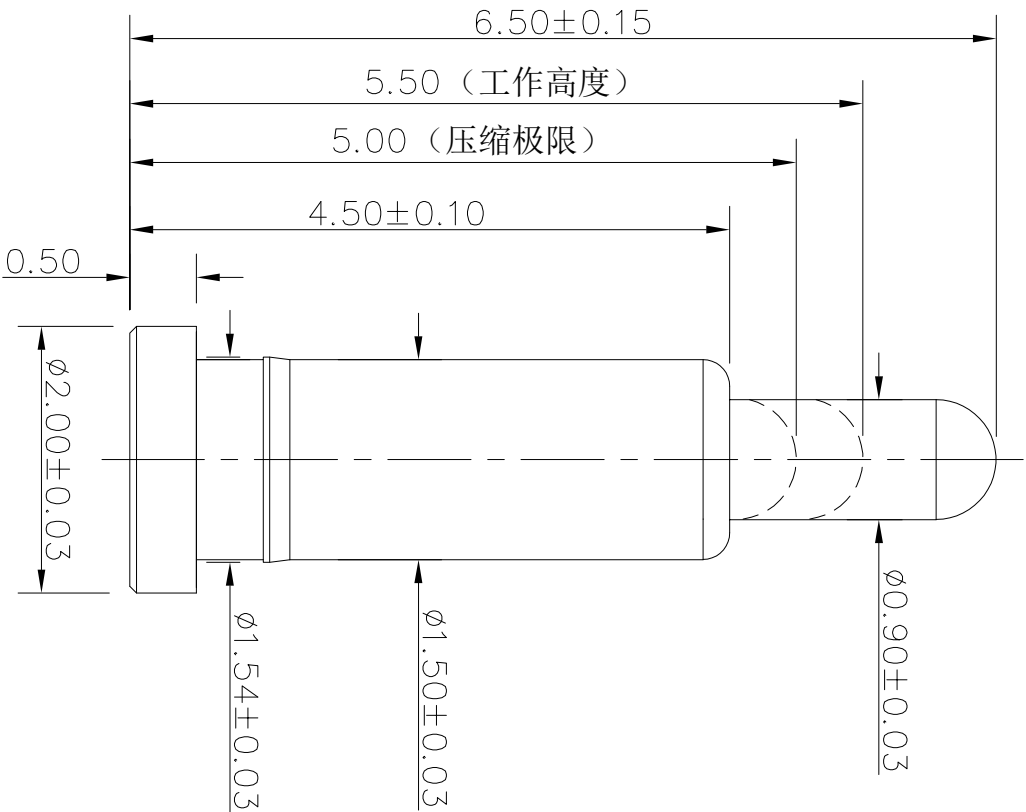

Note:

1: Material(材料) :

Barrel: Brass C3604 (针管: 黄铜 C3604)

Plunger: Brass C3604 (针头: 黄铜 C3604)

Spring: SUS304 (弹簧: SUS304)

2: Plating(电镀) :

Barrel: 3u' Au over 50~80u' Ni(针管: 镀金3u', 镍底50~80u'.)

Plunger: 3u' Au over 50~80u' Ni (针头: 镀金3u', 镍底50~80u'.)

Spring: No plated (弹簧: 不电镀)

3: Electrical(电气特性) :

Rated Current & Voltage: DC 12V;2A (额定电压&电流: 直流12V,2A)

Contact Resistance: 50 mohm Max. at working height.

接触电阻: 最大50毫欧 (在工作高度状态下)

4: Mechanical(机械性能) :

Force: 120g $\pm$ 20% at working height. (120g $\pm$ 20% 在工作高度)。

Durability: 10.000 cycles(min) (寿命: 10000次)

5: WorkTemperature(工作环境):

Withstanding Higt Temperature: 280℃

Operational Temperature: -40℃~+85℃

SCALE:				UNIT		mm		THE UNMARKED TOLERANCE ARE AS BELOW :				DESIGNED BY:		DWG. NO.		YZ147215065R-01	
SHEET:				PROJECTION		A.0		LENGTH				CHECKED BY:		TITLE:		Pogo pin	
DATE:				VER.		A.0		ANGLE				APPROVED BY:					
1 of 1								X.XX ±0.05mm									
2026.04.21								X.XX ±0.10mm									
								X.XX ±2.00°									

深圳市鑫探技术有限公司

HTTP://WWW.XYZPOGOPIN.COM

TEL:0755-28773277 FAX:0755-28891353

