



Pin number

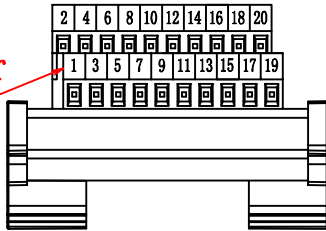

parameter table:

Num	Category	Describe
1	Max Current	0.8A
2	Cable gauge (AWG)	14-26 AWG
3	IDC Pitch:	Pitch:2.54mm
4	PCB Material	FR4
5	IDC Withstanding voltage	300V AC/MINUTE
6	IDC Operating temperature	-20°C to 105°C
7	Rated voltage according to	UL:E311899
8	Rated current according to	UL:E311899
9	IDC Material:	INSULATOR:PBT 30%GF; CONTACT:COPPER ALLOY
10	Box size w/label	L130*W95*H54mm /
11	Packing	

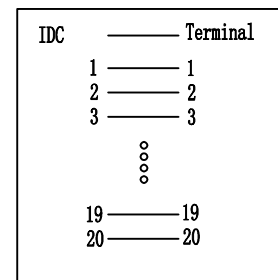

Pin assignment

制作	Hero. Xu	日期	2020.03.24	名称	端子台	型号	IDC20P-C
审核				版本	Ver:1.0	客户编号	
核准				投影角度	图框比例	第 1 张 共 1 张	
<small>未注线性公差GB1804-m级 (单位:mm)</small> 尺寸 $\leq$ 3-6 6-30 30-120 120-400 400-1000 1000-2000 2000-4000 公差 0.1 0.15 0.2 0.3 0.5 0.8 1.2 2.0				角度公差	$\pm 0.5^\circ$	中山市肯博电子科技有限公司 www.kingpow.cn	