



DFN-8 to DIP-12 SMT Adapter (0.5 mm pitch, 3.0 x 2.0 mm body)

| REF. | DIMENSIONS |      |      |        |       |      |
|------|------------|------|------|--------|-------|------|
|      | mm         |      |      | inches |       |      |
|      | MIN.       | TYP. | MAX. | MIN.   | TYP.  | MAX. |
| A    |            | 1.20 |      |        |       |      |
| B    |            | 0.60 |      |        |       |      |
| C    |            | 0.25 |      |        |       |      |
| B2   |            | 0.56 |      |        |       |      |
| C2   |            | 2.15 |      |        |       |      |
| D    |            | 0.25 |      |        |       |      |
| D2   |            | 0.32 |      |        |       |      |
| E    |            | 0.50 |      |        |       |      |
| F    |            |      |      |        | 0.600 |      |
| G    |            |      |      |        | 0.100 |      |
| H    |            |      |      |        | 0.025 |      |

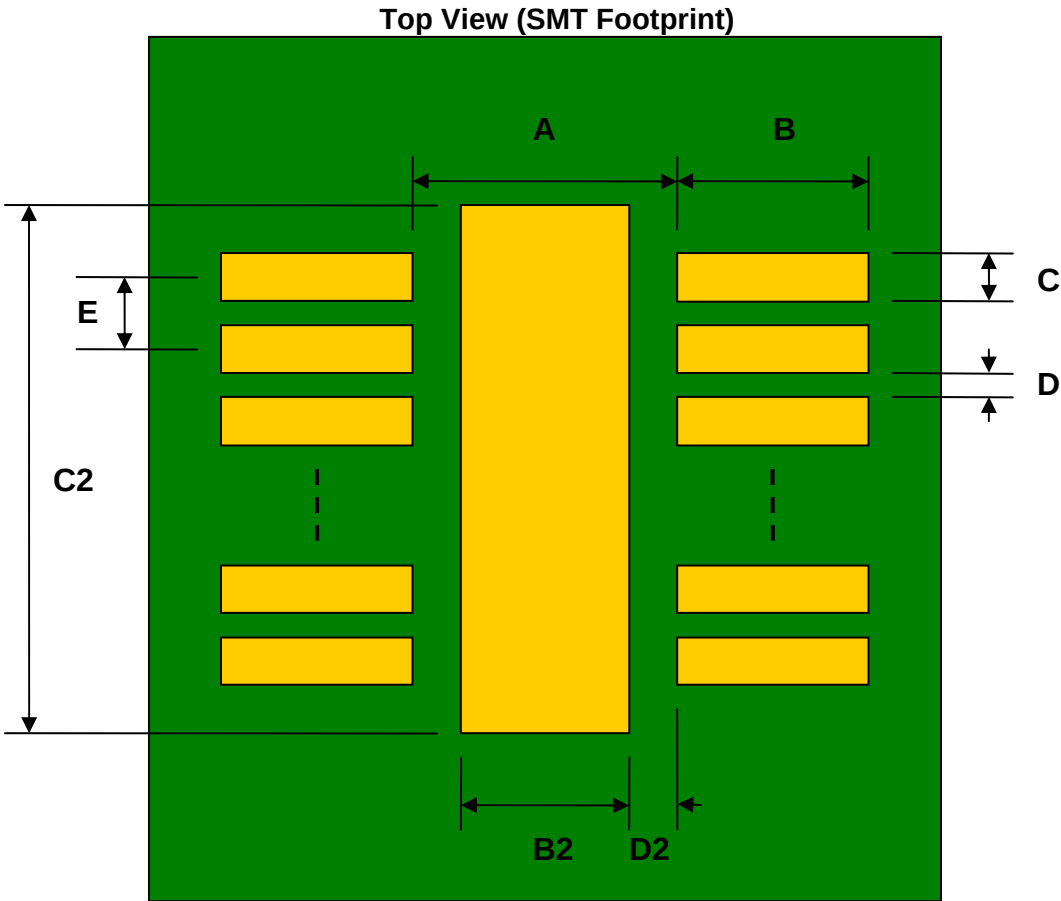


(Representative drawing only - not to scale)

**Bottom View (DIP Pins)**

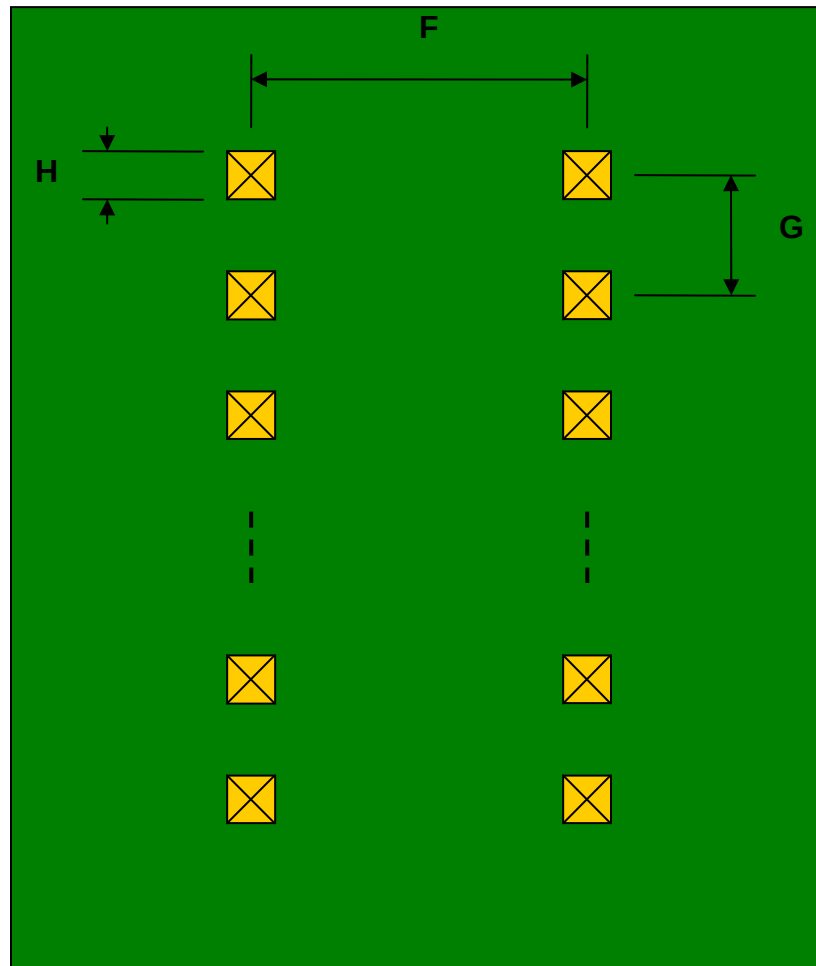

(Representative drawing only - not to scale)

**Side View (DIP Pins)**

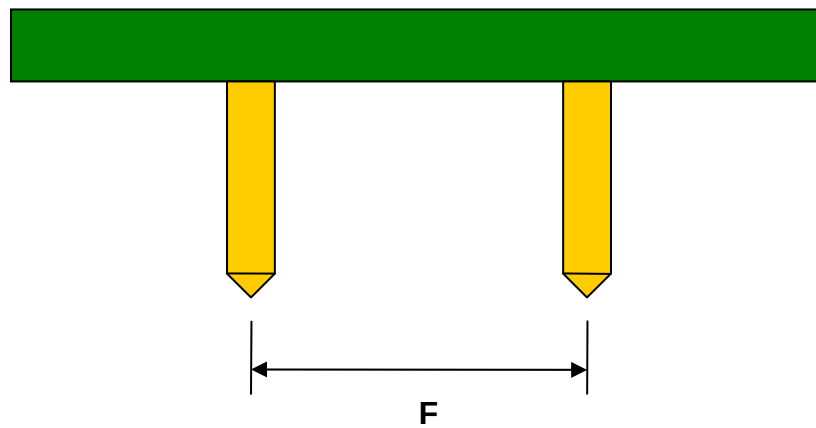

(Representative drawing only - not to scale)