


RoHS Compliant

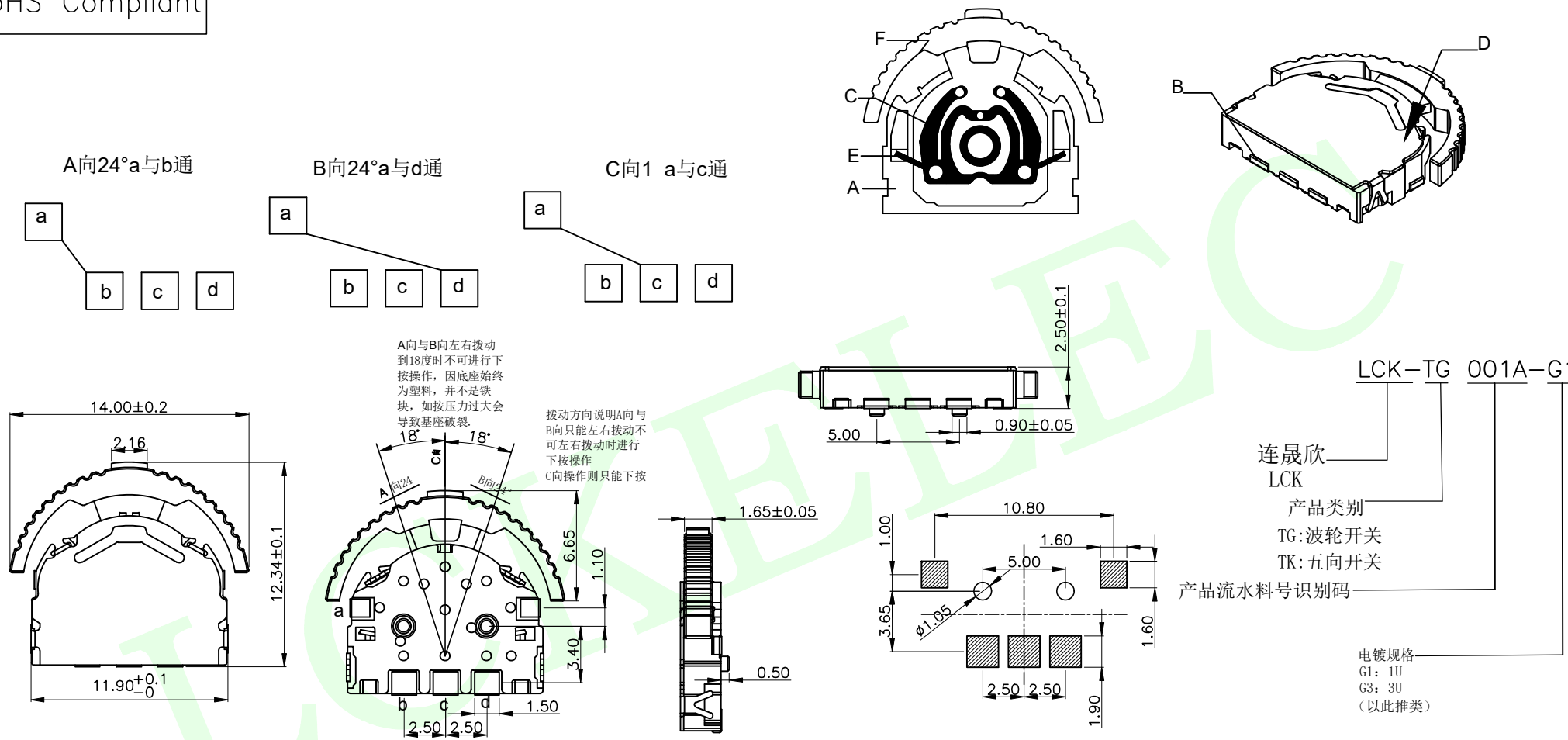

LCK-TG 001A-G1

连晟欣  
LCK  
产品类别  
TG: 波轮开关  
TK: 五向开关  
产品流水料号识别码

电镀规格  
G1: 1U  
G3: 3U  
(以此类推)

项 目		标 准	
电气性能	额定电流 Rated Current:	0.1A MAX	
	额定电压 Rated voltage:	DC 12V	
	接触电阻 Contact resistance:	≤100mΩ	
	绝缘电阻 Insulation Resistance:	≥100MΩ	
机械性能	耐压强度 Compressive strength:	AC110V 50Hz/1 min	
	操作力度 Operating force:	2-80±50gf 205±50gf	
	机械寿命 Mechanical life:	10,000 cycles Min	
环境性能	操作行程 Operation Stroke:	1.0±0.2mm	
	温度范围 Temperature Range:	-10°C ~ +60°C	

NO.	零件名称 Part Name	QTY	材 料 Material	镀涂 Plating coating	颜色 colour	备注 Remarks
F	手柄	1	尼龙	/	黑色	
E	弹簧	1	不锈钢丝	/	原色	
D	盖板	1	不锈钢	/	原色	
C	簧片	1	覆银铜	单边覆银	白色	
B	嵌件	1	磷铜	整体镀银	银白色	
A	底座	1	尼龙	/	黑色	

MEASURE POINT:	QUADRANT POINT (QP)	TANGENCY POINT (TP)	INTERSECTION POINT (IP)
UNLESS OTHERWISE SPECIFIED, TOLERANCE:			
X. ±0.25			
X.x ±0.20			
X.xx ±0.15			
ANGULAR ±3°			

				<b>联晟欣连接器 (深圳) 有限公司</b> Lianshengxin Connector (Shenzhen) Co., Ltd	
DESIGN	Andy	DATE	2014.12.24	TITLE: Wheel switch series	
CHECKED		DATE			
APPROVED		DATE			
PART NO: LCK-TG001A-G1				REV: 04	SCALE: 1:1
DRAWING NO:				UNIT: mm	SHEET: 1/1