 


OIL TIGHT Miniature Incandescent Indicators

FOR MOUNTING IN 11/16" CLEARANCE HOLE



T-3 1/4
MINIATURE
BAYONET BASE

See lamp ratings
on page K.

Recognized under the component
program of Underwriters'
Laboratories Inc.




MATERIALS AND FINISHES

- **Mounting Bushing:** Brass, white nickel finish. Optional, black nickel finish.
- **Lens Holder:** Brass, satin chrome finish. Optional, polished chrome or black nickel finish.
- **Internal-tooth-Lockwasher:** Phosphor bronze, white nickel finish.
- **Mounting Nut:** Brass, white nickel finish.


How to designate the three digit part number suffix (-XXX)

FINISH	RESISTOR	HARDWARE
1-WHITE NICKEL	0-NONE	3-WATER-TIGHT, OIL TIGHT ON THE FACE OF THE PANEL
2-BLACK NICKEL		
3-POLISHED CHROME		
4-SATIN CHROME		

Note: The part numbers given in this catalog indicate standard indicator lights. The above table provides the standard and optional designations for Finish and Resistor where appropriate.

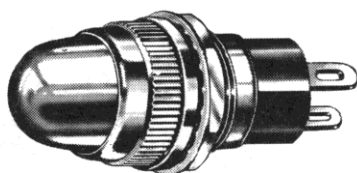

125-0410-1111-403
Stovepipe lens

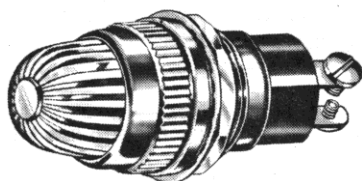

125-1310-1191-403
Stovepipe lens

125 SERIES

BASE PART NUMBERS

screw terminals	soldering terminals	quick connect terminals
125-1310-11-103	125-0410-11-103	125-5710-11-103

CAP PART NUMBERS

COMPLETE ASSEMBLY PART NUMBERS

CAP PART NUMBERS	COMPLETE ASSEMBLY PART NUMBERS		
STOVEPIPE 125-1111-403 back frosted 125-1131-403 unfrosted	125-1310-1111-403	125-0410-1111-403	125-5710-1111-403
	125-1310-1131-403	125-0410-1131-403	125-5710-1131-403
STOVEPIPE 125-1191-403 internal fluting	125-1310-1191-403	125-0410-1191-403	125-5710-1191-403

Part numbers shown in gray are normally
in inventory at your Dialight Distributor.

Order complete with lamp to be assured of receiving the
indicator light and correct lamp together for immediate use.