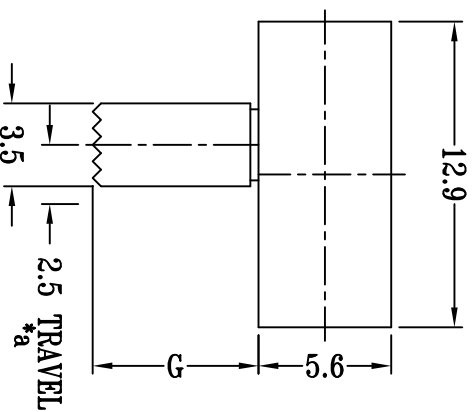




SK-12E12-GXXX

横柄
G-Switch P/N

Switch Height (mm)	
G020=2.0	G030=3.0
G040=4.0	G050=5.0
G055=5.5	G060=6.0
G065=6.5	G070=7.0
G075=7.5	G080=8.0
G085=8.5	G090=9.0
G095=9.5	G100=10.0

G-Switch Specification:

Electrical Specifications: 1.0A/DC24V
Contact resistance (CR): $\leq 50\text{m}\Omega$
Insulation Resistance(IR): $\geq 100\text{M}\Omega$ DC250V
Compressive strength (WV): AC250V 1minute
Operating temperature: $-25^{\circ}\text{C}\sim+70^{\circ}\text{C}$
Storage humidity: $<85\%\text{RH}$
Electrical life: 10,000Cycles.

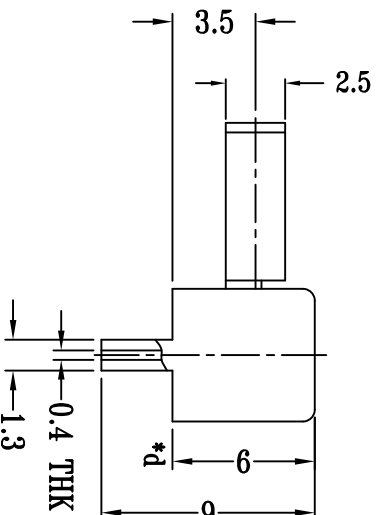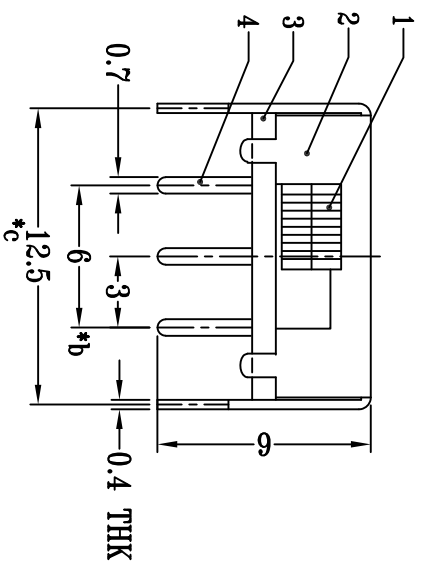

注: “*” 表示关键尺寸 (4个)



G-Switch Electronic (HongKong) CO.,Ltd.

Unless otherwise
specified, Tolerance:
X ± 0.30
X.X ± 0.20
X.XX ± 0.15
X.XXX ± 0.10
Angles $\pm 5^{\circ}$

DESIGN Bright Lee DATE 2016.05.29
CHECKED DATE
APPROVED DATE
<http://www.dg-switch.com>

Mold code:

SK-12E12-GXXX

REV.: X1 SCALE: 4:1 UNIT: mm
SIZE: A4 SHEET: 1/1

TEL:0769-82388879



ROHS
Compliant
2002/95/EC

