
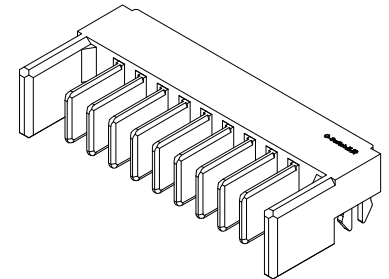
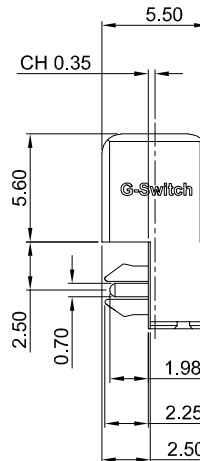
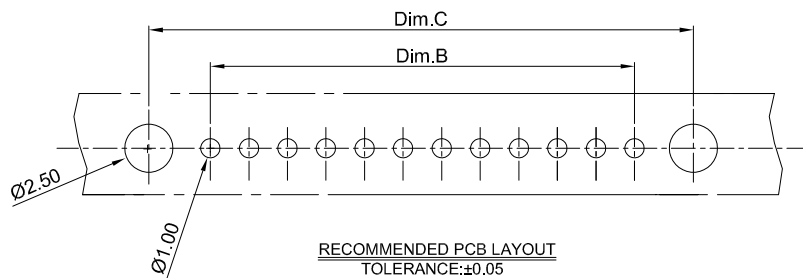
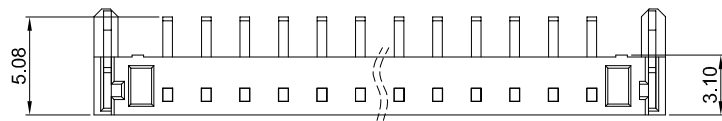
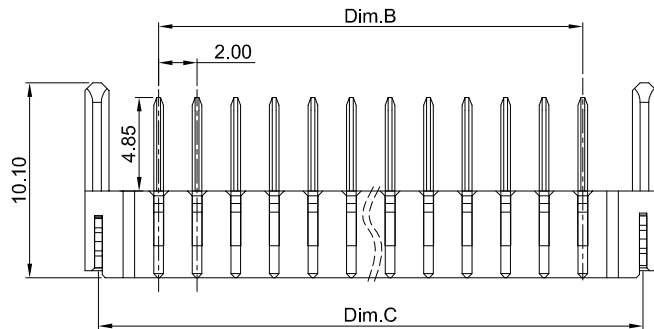


A B C D E

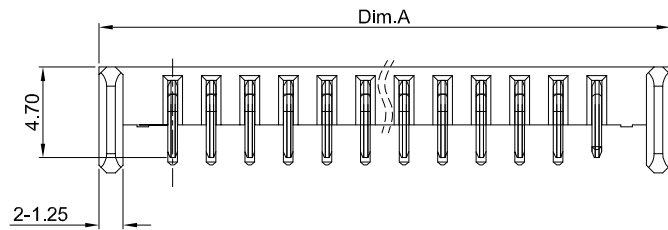

GT-BT P 200 08 - 0550 B - 027 A

G-Switch

Series
BT: Battery

Type
P: Plug

Pitch
200=2.00

Pin Q' PY
02~15

Height
0550=5.5

Detail

Serial code

Detail
B:No oolumn

G-Switch Specification:

- 1.Current rating: 5A
- 2.Rated Voltage: 30V DC
- 3.Insulation resistance: 100MΩ min
- 4.Contact resistance: 30mΩ max
- 5.Dielectric strength: 500V RMS
- 6.Durability: 5000cycles
- 7.Operating temperature range: -40°C ~ +85°C

3	FIXED FEET	STAINLESS STEEL	Sn
2	CONTACT	PHOSPHOR BRONZE	Au ON CONTACT AREA
1	HOUSING	LCP,94V-0	BLACK
NO.	PART NAME	MATERIAL	REMARK

Ordering Information:

Circuit	Dimensions(mm)			Circuit	Dimensions(mm)		
	A	B	C		A	B	C
02	9.65	2.00	8.25	09	23.65	16.00	22.25
03	11.65	4.00	10.25	10	25.65	18.00	24.25
04	13.65	6.00	12.25	11	27.65	20.00	26.25
05	15.65	8.00	14.25	12	29.65	22.00	28.25
06	17.65	10.00	16.25	13	31.65	24.00	30.25
07	19.65	12.00	18.25	14	33.65	26.00	32.25
08	21.65	14.00	20.25	15	35.65	28.00	34.25



RoHS
Compliant
EU RoHS Standards



SCALE: 1:1 UNIT: mm
SIZE: A4

Unless otherwise
General Tolerance:

X ±0.50
X.x ±0.30
X.xx ±0.20
X.xxx ±0.10
X" ±2°

Title: Horizontal Pitch2.0 Battery Conn DIP
Mid-Mount2.5 CH=0.35 L×10.1×H5.5mm

Molde Code: GT-BTP20008-0550B-027A

DRAWN	CHECKED	APPROVED	DATE
Xia	Chen	Chen	2023.12.28

品赞科技®
b-Switch
www.dg-switch.com

REV: A0 SHEET: 1/1

A B C D E