
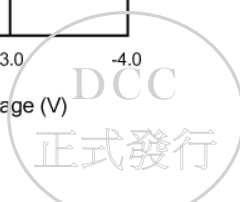
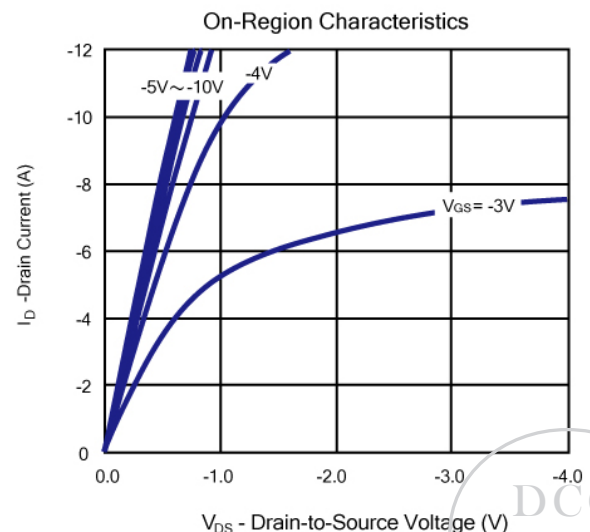
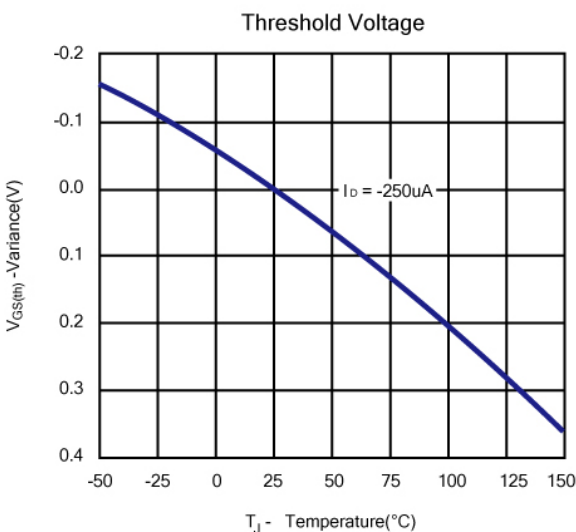
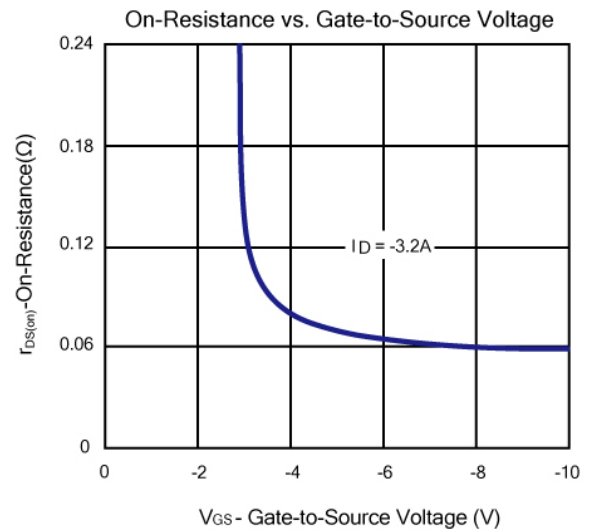
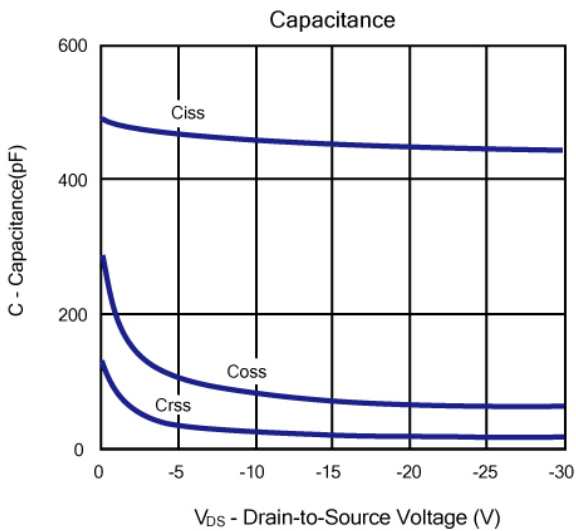
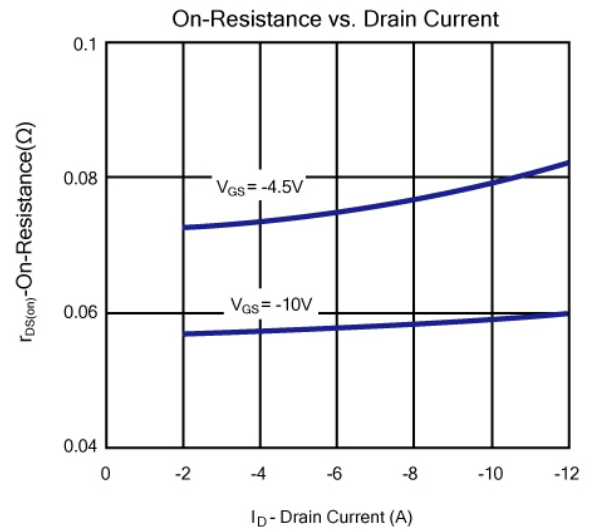






P-Channel 30V (D-S) MOSFET

Typical Characteristics (T_J = 25°C Noted)

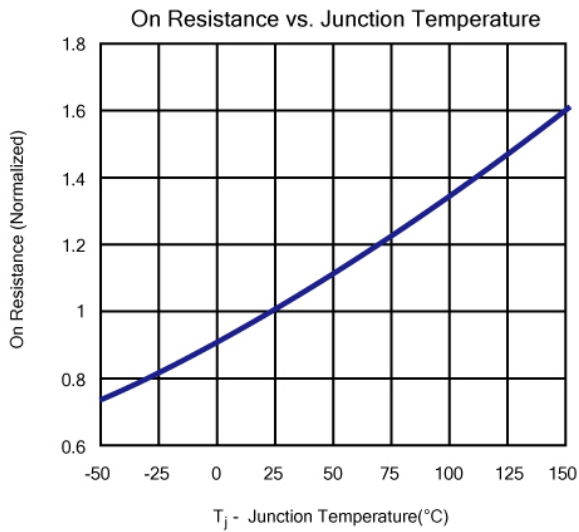


P-Channel 30V (D-S) MOSFET

Typical Characteristics (T_J = 25°C Noted)

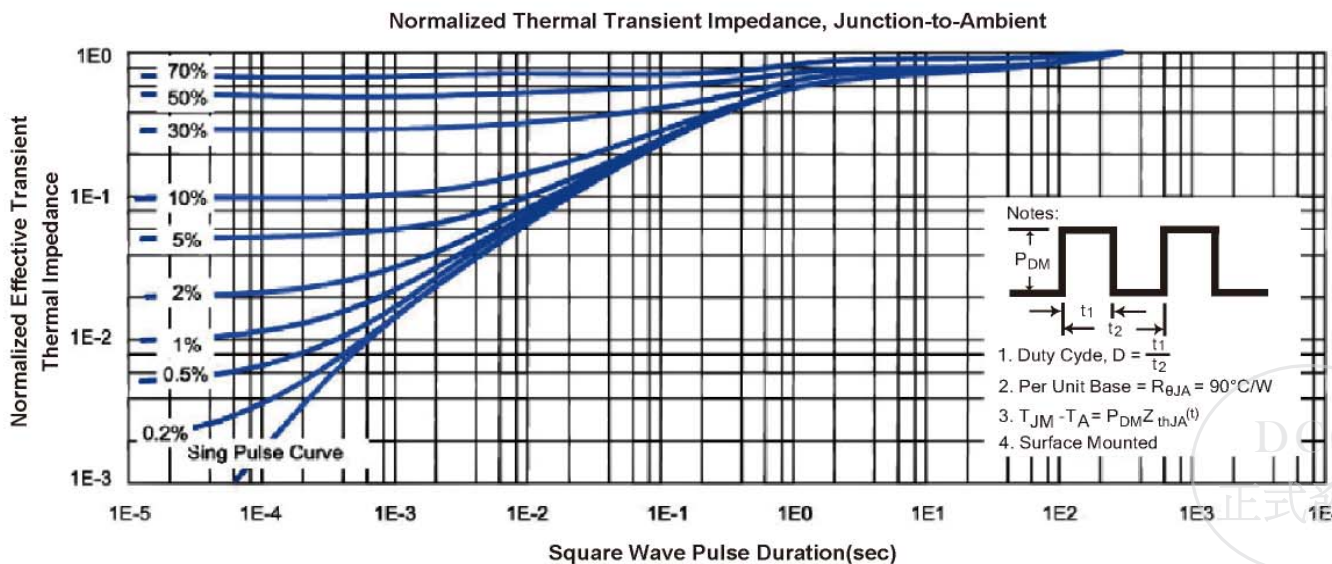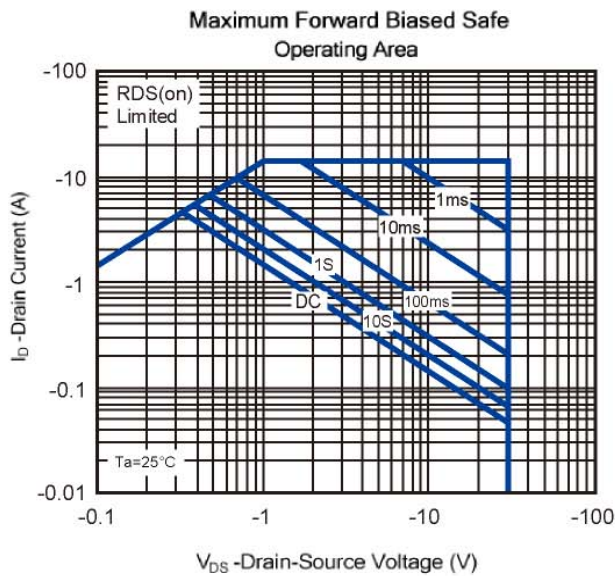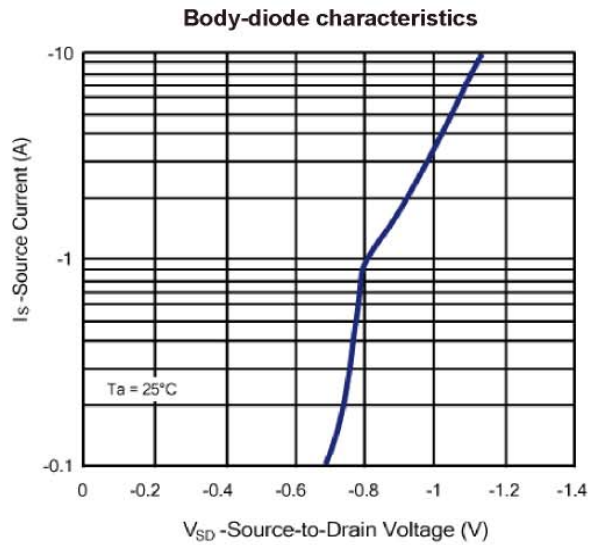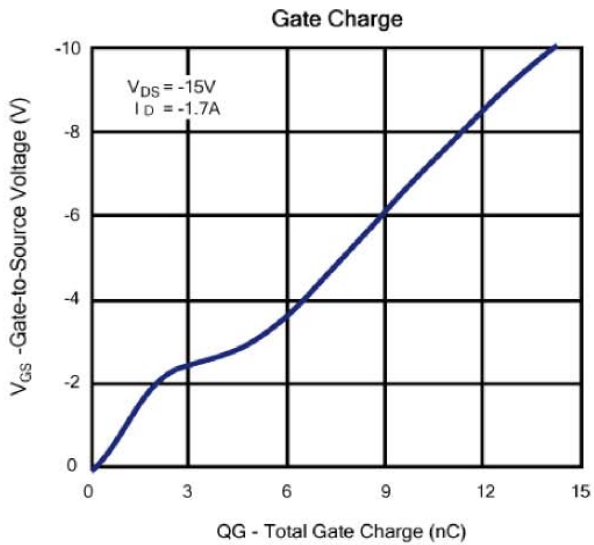

SOT-23 Package Outline

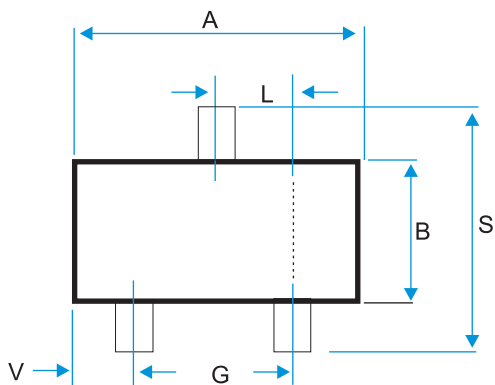

DIM	MILLIMETERS (mm)	
	MIN	MAX
A	2.800	3.00
B	1.200	1.70
C	0.900	1.30
D	0.350	0.50
G	1.780	2.04
H	0.010	0.15
J	0.085	0.20
K	0.300	0.65
L	0.890	1.02
S	2.100	3.00
V	0.450	0.60

