


XRCGB24M000F0L00R0

目前生产 RoHS REACH

外观 & 形状

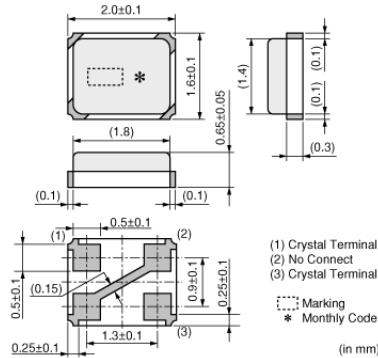

特点

The crystal unit that realized small package and highly accurate frequency.

Based on Murata's excellent package technology and high grade quartz crystal elements, achieving small size and high accuracy resonators.

Features

1. The series is available in the applications to be necessary for high accuracy resonator. Especially, it is the best for the communication clocks such as S-ATA and USB2.0.
2. The resonator is extremely small size (2.0 x 1.6 x 0.7 (mm)), and contribute to reduction in mounting area.
3. The series complies to RoHS directive, being lead-free (phase 3).

用途

其他用途	消费级
------	-----

包装信息

包装	规格	最小订购单位
R0	180mm塑料编带	3000

注意

1. 本目录是从株式会社村田制作所网站中下载的。规格若有变更，或若其中产品停产，请在订购时确认，恕不另行通知。
2. 本目录因没有足够的空间说明详细规格，仅载明标准规格。因此，在订购产品之前，请核准其规格或者办理产品规格表。

XRCGB24M000F0L00R0

规格


型号	HCR2016
频率	24.0000MHz
频率公差	±100ppm max. (25±3°C)
工作温度范围	-30°C to 85°C
频率温度特性	±50ppm max.
频率老化	±50ppm max.
清洗	Not available
负载电容量	6pF
等效串联电阻(max.)	150Ω
驱动电平(max.)	300μW
形状	SMD

注意

1. 本目录是从株式会社村田制作所网站中下载的。规格若有变更，或若其中产品停产，请在订购时确认，恕不另行通知。
2. 本目录因没有足够的空间说明详细规格，仅载明标准规格。因此，在订购产品之前，请核准其规格或者办理产品规格表。

XRCGB24M000F0L00R0

产品数据

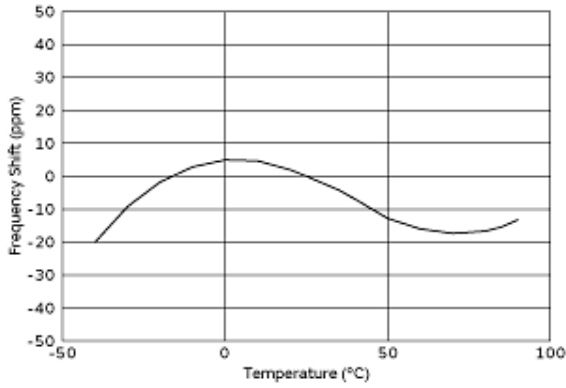

温度特性

注意

1. 本目录是从株式会社村田制作所网站中下载的。规格若有变更，或若其中产品停产，请在订购时确认，恕不另行通知。
2. 本目录因没有足够的空间说明详细规格，仅载明标准规格。因此，在订购产品之前，请核准其规格或者办理产品规格表。