

Model(型號): DS-02-R-T 2.54mm 2POS DIP


KE Switches



※ Features:

- ▶ Lowest contact resistance less than 50mΩ.
- ▶ Gold-plated contact provides high reliability.
- ▶ All materials are UL 94V0 grade, high temperature resistant plastic.
- ▶ All DIP switches Packaging are IC TUBES and the switches are OFF state.
- ▶ Shell colour: Red or Blue or Black.

※ Dimensions(規格圖): DS Series

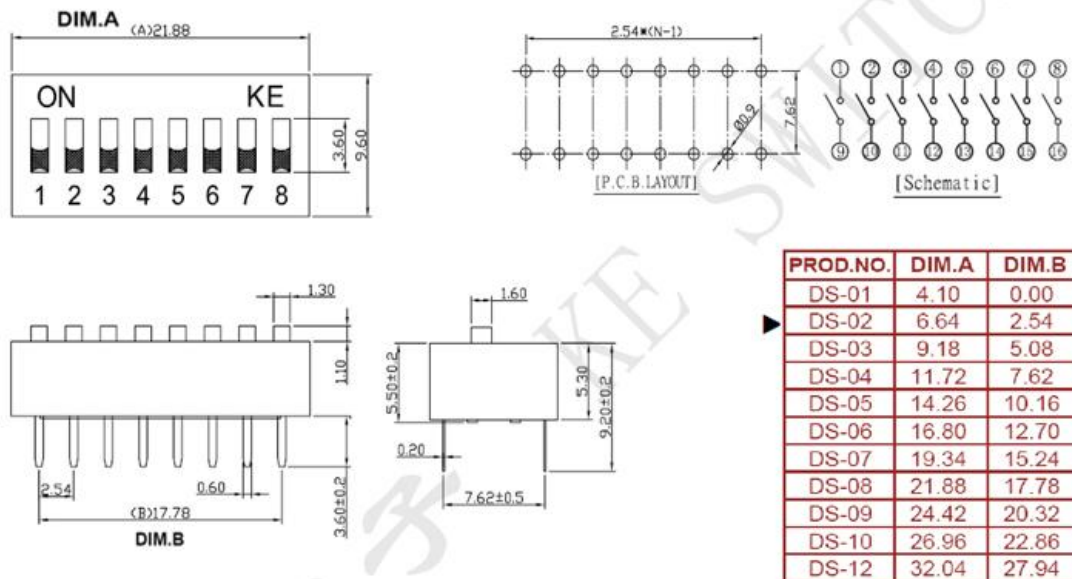

※ Specifications(規格)

● Electrical Characteristics   電氣性能	
Positions [位數]	▶ <input type="checkbox"/> 1 <input checked="" type="checkbox"/> 2 <input type="checkbox"/> 3 <input type="checkbox"/> 4 <input type="checkbox"/> 5 <input type="checkbox"/> 6 <input type="checkbox"/> 7 <input type="checkbox"/> 8 <input type="checkbox"/> 9 <input type="checkbox"/> 10 <input type="checkbox"/> 12
Contact Rating [触点容量]	▶ Switching: DC24V 25mA Non-Switching: DC50V 100mA
Contact resistance [接觸阻抗]	▶ 50mΩ Max at initial : 100mΩ Max after life test
Insulation resistance [絕緣阻抗]	▶ 1000MΩ Min at DC500V
Dielectric strength [耐電壓]	▶ 1 minute at AC 500VAC
Wave soldering [波峰焊]	▶ 255±5°C for 3----5 Seconds
● Mechanical Characteristics   機械性能	
Circuit [開關形式]	▶ SPST
Operation force [動作力]	▶ 1000gf Max
Operating Temperature Range [工作溫度範圍]	▶ -30°C~85°C
Storage Temperature Range [儲存溫度範圍]	▶ -40°C~85°C
Packing Specifications [包裝規格]	▶ 74 PCS / Tube, 3700 PCS / Box
● Endurance Characteristics   耐久性能	
Mechanical life [機械壽命]	▶ 3,000 Cycles Operations

Http://www.kswitch.com

Email:kswitch@126.com

TEL:(86)0769-82633166

FAX:(86)0769-82633255