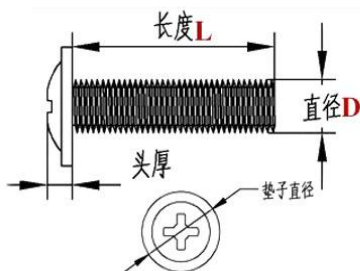


深圳市顺天五金制品有限公司

产品规格书

客户： 深圳市立创商城		图样：参考样  <table border="1" style="width: 100%; margin-top: 10px;"> <thead> <tr> <th colspan="2">单位：mm</th> <th colspan="2">尺寸为手工测量以实物为准</th> </tr> <tr> <th>螺纹直径</th> <th>头部直径</th> <th>圆头厚度</th> <th>螺纹长度 (注明：圆头螺丝长度不算总长不包括头部)</th> </tr> </thead> <tbody> <tr> <td>M2</td> <td>5.3</td> <td>1.5</td> <td>4/5/6/8/10/12</td> </tr> <tr> <td>M2.5</td> <td>5.3</td> <td>1.5</td> <td>5/6/8/10/12</td> </tr> <tr> <td>M3</td> <td>7.0</td> <td>1.8</td> <td>4/5/6/8/10/12/16/20</td> </tr> <tr> <td>M4</td> <td>8.2</td> <td>2.2</td> <td>4/5/6/8/10/12/16/20</td> </tr> <tr> <td>M5</td> <td></td> <td></td> <td></td> </tr> <tr> <td>M6</td> <td></td> <td></td> <td></td> </tr> </tbody> </table>			单位：mm		尺寸为手工测量以实物为准		螺纹直径	头部直径	圆头厚度	螺纹长度 (注明：圆头螺丝长度不算总长不包括头部)	M2	5.3	1.5	4/5/6/8/10/12	M2.5	5.3	1.5	5/6/8/10/12	M3	7.0	1.8	4/5/6/8/10/12/16/20	M4	8.2	2.2	4/5/6/8/10/12/16/20	M5				M6			
单位：mm					尺寸为手工测量以实物为准																															
螺纹直径	头部直径				圆头厚度	螺纹长度 (注明：圆头螺丝长度不算总长不包括头部)																														
M2	5.3				1.5	4/5/6/8/10/12																														
M2.5	5.3				1.5	5/6/8/10/12																														
M3	7.0	1.8	4/5/6/8/10/12/16/20																																	
M4	8.2	2.2	4/5/6/8/10/12/16/20																																	
M5																																				
M6																																				
供应商名称： 深圳市顺天五金制品有限公司																																				
规格名称：螺丝PWM2/3/4 X(4, 5, 6, 8, 10, 12) *6/7系列																																				
客户料号：																																				
样品数量： 20 PCS																																				
日期： 2019-01-23																																				
外观检验	<input checked="" type="checkbox"/> 客户标准	AC	0	0																																
	样板数量： 20	NG	0	1																																
尺寸与功能检验(抽样按工作指引) (单位:mm)																																				
检验项目	检验标准	样本数 (PCS)	不良数 (PCS)	检验工具	测试数据, 判定结果																															
直径: D	φ 3.0MM +0/-0.15	20	/	游标卡尺	2.93/2.92/2.92/2.92/2.93 OK																															
长度: L	6.00 MM +/-0.2	20	/	游标卡尺	5.93/5.95/5.98/6.00/5.95 OK																															
垫子直径:	7.00 MM +/-0.2	20	/	游标卡尺	7.00/6.99/7.01/7.06/6.95 OK																															
头厚:	1.8 MM ±0.2	20	/	游标卡尺	1.75/1.83/1.75/1.80/1.80 OK																															
材料	材质：1010A 碳钢； 表面处理：加硬 镀镍																																			
判定结果	<input checked="" type="checkbox"/> 合格			客户 确认																																
	<input type="checkbox"/> 不合格																																			
检验员：张红		审核：钟生		批准：赖生																																
日期： 2019-01-23		日期： 2019-01-23		日期： 2019-01-23																																

附图