

T1C

**FEATURES**

- ※Miniature 2.8\*1.95mm
- ※Side push mid-mount type
- ※300,000 operation life cycles
- ※Better soldering peeling strength
- ※Height from surface of PCB:0.975mm


**APPLICATION**

- ※Smart phone
- ※Medical
- ※Portable electronic device
- ※3C products


**SPECIFICATION**

Contact Rating	10uA,2V DC to 20mA,15V DC
Contact Resistance	500mΩ max.
Insulation Resistance	50MΩ min. 100V DC
Dielectric Strength	250V AC/1 minute
Operating Force	160±50gf
Travel	0.13mm
Operating Life	300,000 cycles
Operating Temp.	-40°C ~ +85°C
Storage Temp.	-40°C ~ +85°C

**HOW TO ORDER**

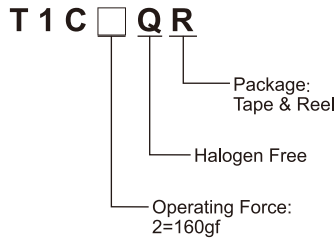

**CIRCUIT**

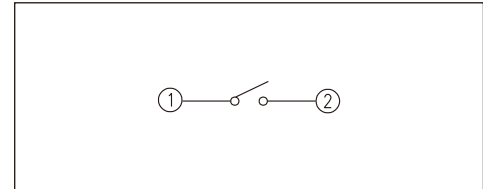

**PACKAGE**

<Tape & Reel>  
6000 pcs

TACT SWITCH

**T1C**

