
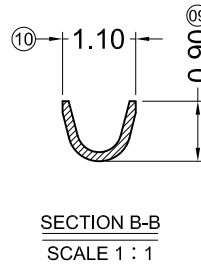
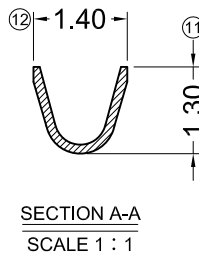


■ Specifications :

- Voltage rating: 50V AC / DC
- Current rating: 1A AC / DC
- Withstanding voltage: 500V AC/minute
- Temperature range: -25°C~+85°C
- Insulation resistance: ≥100MΩ
- Contact resistance: ≤20mΩ
- After environmental testing: ≤40mΩ

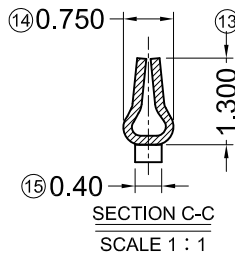

T1010PS-03				Stamping Before Plating:30~50u" Ni/Whole Gold :3u" Min.	P1010
T1010PS-00	Phosphor Bronze	AWG#28-32	0.80mm(Max)	Stamping Before Plating:30~50u" Ni/Whole Gold :Gold Flash	
T1010PS-N2				Stamping Before Plating:50u" Min Ni;120u"Sn Min	
T1010PS-2				Stamping Before Plating:30~50u" Ni;70~120u"Sn	
PART NO	Material	Wire Range	Insulation O.D.	Finish	Used In Housing

				TOLERANCE UNLESS OTHERWISE		DRAWN	CK tan	XFCN兴飞连接器有限公司 CONNECTORS XFCN CONNECTORS CO., LTD.		SHEET	1/1
				X.	±0.30	X°	±5°			CHKD	DATE
				.X	±0.20	.X°	±2°	APPD	PRODUCT NAME	1.00mm Crimp Style Connectors	
				.XX	±0.08	.XX°	±1°	VIEW	PART. NO.	T1010PS-2	
				.XXX	±0.03	.XXX°	±0.5°		DWG. NO.	009	
AO	MODIFICATION		DRAW	DATE							