

## 數位溫濕度計使用說明書

### 一、產品規格及功能

- 1、日曆顯示功能
- 2、每日鬧鐘功能
- 3、整點報時功能
- 4、°C/°F溫度顯示
- 5、12/24 小時制時鐘
- 6、8 分鐘貪睡功能
- 7、5 秒 LED 背光顯示功能
- 8、星期顯示功能
- 9、溫度測量範圍: -10°C~50°C/ 14°F~122°F
- 10、溫度測量精度: ±1°C
- 11、相對濕度測量範圍: 10%~95%
- 12、濕度測量精度: ±5%
- 13、溫度與濕度取樣週期: 10 秒
- 14、最高/最低溫度與相對濕度顯示


### 二、產品描述



- ① 顯示視窗
- ② 背光控制/貪睡功能
- ③ °C/°F轉換
- ④ 最高/最低溫度和相對濕度
- ⑤ 調整設置
- ⑥ 模式轉換



- ① 蜂鳴器
- ② 電池位置
- ③ 磁鐵

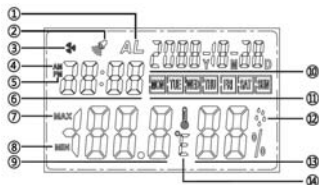

- ① 鬧鐘模式
- ② 整點報時
- ③ 鬧鐘
- ④ 上午
- ⑤ 下午
- ⑥ 時間顯示
- ⑦ 最高值
- ⑧ 最低值
- ⑨ 溫度顯示
- ⑩ 年/月/日顯示
- ⑪ 星期顯示
- ⑫ 濕度符號
- ⑬ 濕度顯示
- ⑭ 溫度單位°C/°F轉換

### 三、操作功能

#### 出廠預設值

時間: AM 12:00 / 12 小時制  
日期: 2012/1/1  
星期: SUN  
鬧鐘: AM 12:00  
溫度顯示單位: °C

#### 按鍵說明

##### MODE 鍵

- 1) 切換時鐘顯示模式: 可設置時鐘、鬧鐘、年/月/日與 12/24 小時制。
- 2) 按 MODE 鍵 1 秒, 顯示鬧鈴設定時間。
- 3) 長按 MODE 鍵 2 秒, 設定順序為: 分→小時→12/24→年→月→日→退出設置。

##### ADJ 鍵

- 1) 關閉鬧鐘和整點報時
- 2) 用於各項功能鍵: 數值設置調整

##### LIGHT/SNOOZE 鍵

- 1) 按此鍵可點亮背光 5 秒
- 2) 鬧鐘響鬧時, 按此鍵可啟動 8 分鐘貪睡功能。

##### °C/°F 鍵

切換溫度°C/°F顯示方式。

##### MIN / MAX 鍵

- 1) 顯示已記憶之最高/最低溫度/濕度。
- 2) 按 MAX / MIN 鍵, 溫濕度最高值→溫濕度最低值→目前溫濕度。

##### 功能設置

###### 設置時間顯示

- 1) 長按 MODE 鍵 2 秒, 設定分/小時。
- 2) 按 ADJ 鍵, 設置時間數值。


###### 設置 12/24 小時制顯示

- 1) 長按 MODE 鍵 2 秒, 設定 12/24 小時制。
- 2) 按 ADJ 鍵, 設置數值。

###### 設置年/月/日顯示

- 1) 長按 MODE 鍵 2 秒, 設定年/月/日, 系統會自動調整星期。
- 2) 按 ADJ 鍵, 設置時間數值。

###### 設置鬧鐘時間及關閉

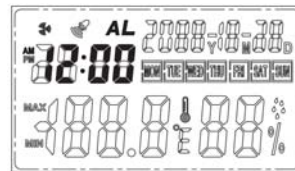

###### 鬧鐘時間設置

- 1) 按 MODE 鍵 1 秒, 切換至鬧鈴模式。
- 2) 長按 MODE 鍵 2 秒, 設定分鐘及小時。
- 3) 按 ADJ 鍵, 設置時間數值。
- 4) 按 MODE 鍵退出

###### 鬧鐘關閉設置


- 1) 按 MODE 鍵 1 秒, 切換至鬧鈴模式。
- 2) 按 ADJ 鍵, 關閉/開啟鬧鈴。
- 3) 按 MODE 鍵退出
- 4) 當鬧鐘響鬧時, 請按任意鍵(除了 LIGHT/SNOOZE 鍵)解除鬧鐘, 終止響鬧。

### 設置貪睡功能


當鬧鐘響起時, 按 LIGHT/SNOOZE 鍵開啟 8 分鐘貪睡功能。

### 溫度/濕度最高/最低記憶顯示


- 1) 按 MAX / MIN 鍵 1 下, 顯示所記憶的溫度/濕度最高值。

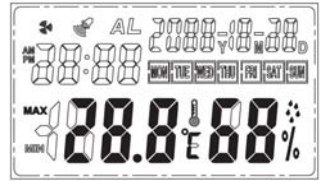

- 2) 接著再按 MAX / MIN 鍵 1 下, 顯示記憶中溫度/濕度最低值。

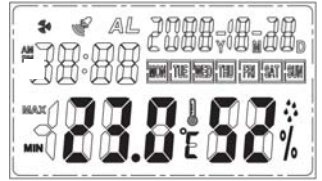

- 3) 再按 MAX / MIN 鍵 1 下, 回復當前溫度/濕度顯示。

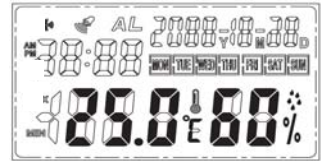

### 注意:

1. 以上設置, 在 1 分鐘無按鍵操作自動退出。
2. 電池更換後, 所有設定會恢復出廠預設值, 須重新設定。

**Pro'sKit®**

ISO 9001  
CERTIFIED



寶工實業股份有限公司  
http://www.prokits.com.tw  
E-mail: pk@mail.prokits.com.tw

©2015 版權所有, 請勿任意翻印使用(C).

# Mini Digital Temperature Humidity Meter User Manual

**FEATURES:**

1. Date and weekday display
2. Alarm function
3. Hourly chime
4. Eight-minutes snooze
5. 12/24-hour time display
6. °C/°F Temperature unit conversion
7. LED backlight
8. Temp. range: -10°C~50°C/14°F~122°F
9. Temperature accuracy: ±1°C
10. Humidity range: 10%~95%
11. Humidity accuracy: ±5%
12. Max/Min memory function
13. Temp. & humidity value capture: 10secs


**DESCRIPTION:**



- ① Display screen
- ② Backlight/Snooze
- ③ °C/°F Temperature unit conversion
- ④ Max/Min temp. & humidity display
- ⑤ Settings adjustment
- ⑥ Mode switch



- ① Buzzer
- ② Battery
- ③ Magnet

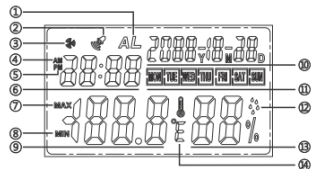

- |                |                         |
|----------------|-------------------------|
| ① Alarm        | ⑧ Min. Value            |
| ② Hourly chime | ⑨ Temperature           |
| ③ Alarm clock  | ⑩ Date                  |
| ④ A.M          | ⑪ Weekday               |
| ⑤ P.M          | ⑫ Humidity mark         |
| ⑥ Clock        | ⑬ Humidity              |
| ⑦ Max. value   | ⑭ °C/°F unit conversion |

**OPERATIONS**

**Default**

Time : AM 12 : 00 / 12 h  
 Date : 2012/1/1  
 Weekday : SUN  
 Alarm : AM 12:00  
 Temp. unit : °C

**Button description**

**MODE**

- 1) Switch clock, alarm, 12/24h, and date.
- 2) Press to display the alarm clock.
- 3) Long press to set up the minute, hour, 12/24h and date.

**ADJ**

- 1) Turn on/off the alarm and hourly chime.
- 2) Adjust the value.

**LIGHT/SNOOZE**

- 1) Press to turn on the backlight for 5secs.
- 2) Press to turn on 8-minutes snooze function when alarm buzzing

**°C/°F**

Press to convert the temperature unit.

**MIN/MAX**

- 1) Press to display the Max./Min. temp. & humidity in memory
- 2) Press one time to display the Max. value, two times for Min. value, and three times to exit.

**Setup**

**TIME SETUP**

- 1) Long press button MODE to set the time.
- 2) Press button ADJ to adjust the value.


**12/24H SETUP**

- 1) Long press button MODE to set 12/24h.
- 2) Press button ADJ to adjust the value.

**DATE SETUP**

- 1) Long press button MODE to set the date and the weekday will be adjusted automatically.
- 2) Press button ADJ to adjust the value.

**ALARM SETUP**

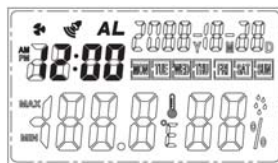

**ALARM CLOCK SETUP**

- 1) Press button MODE to switch alarm.
- 2) Long press button MODE to set the time.
- 3) Press button ADJ to adjust the value.
- 4) Press button MODE to exit.

**On/off setup:**


- 1) Press button MODE to switch alarm.
- 2) Press button ADJ to adjust the value.
- 3) Press button MODE to exit.
- 4) Press any button (except LIGHT/SNOOZE) to turn off the alarm when buzzing.

**SNOOZE FUNCTION SETUP**


when alarm buzzing, press the button LIGHT/SNOOZE to turn on 8-minutes snooze function

**MAX/MIN TEMP. & HUMIDITY DISPLAY**


- 1) Press MAX / MIN one time to display the Max. value

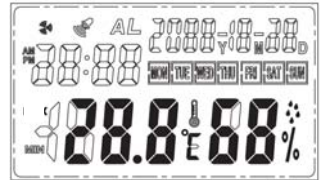

- 2) Press MAX / MIN two times to display the Min. value.

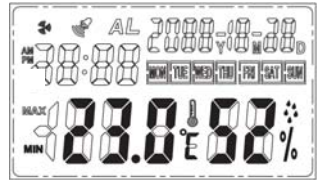

- 3) Press MAX / MIN three times to exit.

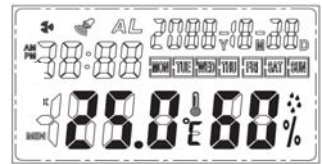

**NOTE:**

1. It will automatically exit if no key is pressed for 1 minute.
2. It will return all the setting to default when replace the battery.

**Pro'sKit®**



PROKIT'S INDUSTRIES CO., LTD.  
<http://www.prokits.com.tw>  
 E-mail: [pk@mail.prokits.com.tw](mailto:pk@mail.prokits.com.tw)