

**SPECIFICATIONS**

**Audio Jack Connector**

**Mechanical**

**Connector Mating Force:** 0.4~3.0kgf (Initial);0.3~3.0kgf (After Life Test).  
**Connector Un mating Force:** 0.4~3.0kgf (Initial);0.3~3.0kgf (After Life Test).  
**Durability:** 1500 Cycles.


**Single HD Jack Series**  
**Right Angle**  
**No Pitch**  
**5 Pos.**

**Electrical**


**Current Rating:** 1A.  
**Contact Resistance:** 50mΩ MAX (Initial);100mΩ MAX (After Life Test) .  
**Dielectric Withstanding Voltage:** 500V AC/min.  
**Insulation Resistance:**100MΩ min.

**Physical**

**Housing:** Thermoplastic, UL 94V-0 rated.  
**Contact:** Copper alloy.  
**Plating:** See "ORDERING INFORMATION".  
**Operating Temperature:** -20°C to +70°C.

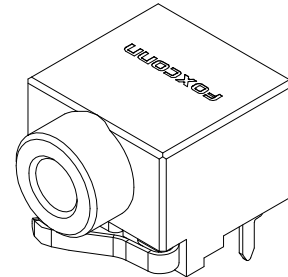


**DRAWING**

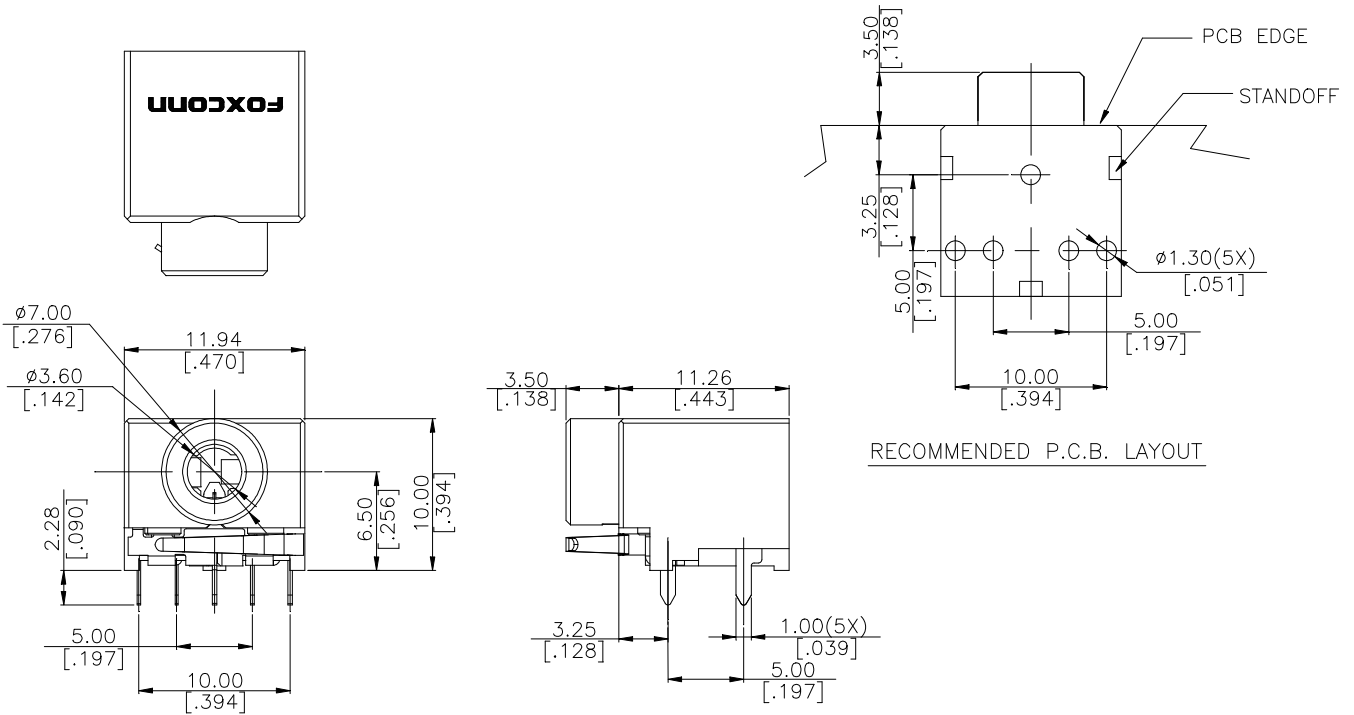

**ORDERING INFORMATION**

**PRODUCT NO.:** JA 1 3 3 3 \* - N 5 \* D - 4 F

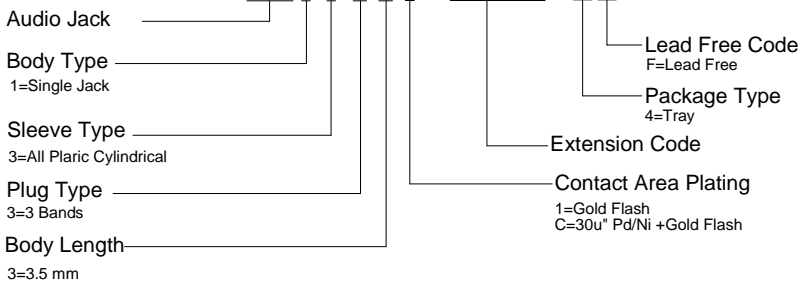

PART NO.	COLOR
JA1333*-N51D-4F	PINK
JA1333*-N54D-4F	LIME
JA1333*-N53D-4F	LIGHT BLUE
JA1333*-N50D-4F	BLACK