


D:21-10-9

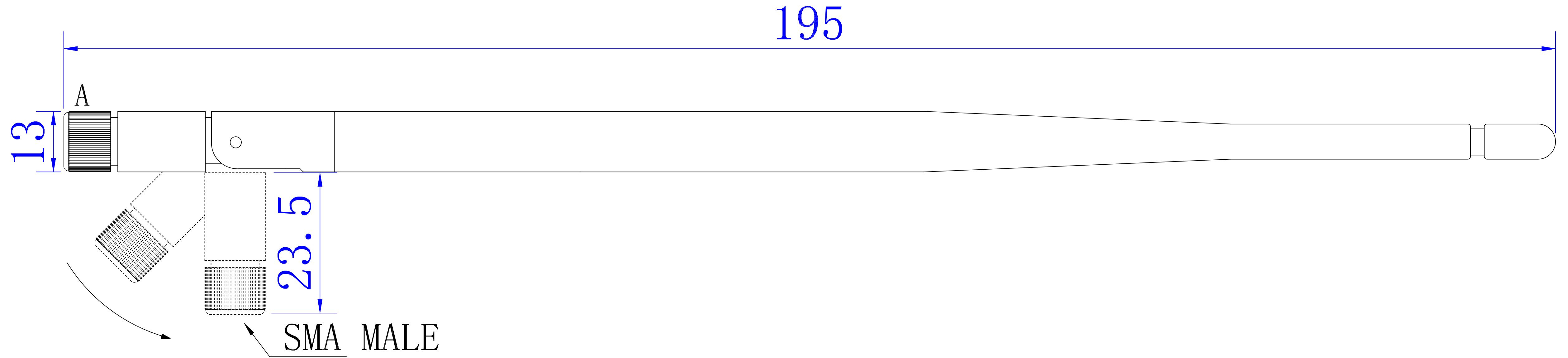

Frequency : 2400-2500MHz  
Gain : 5.0(dBi)  
Impedance : 50 Ω  
VSWR : ≤ 1.8  
Maxi Power : 50W  
Radiation mode : Omni-direction  
Polarization mode : Vertical  
Cable Type : /  
Connector : SMA MALE

包装方式:

1. 50PCS 袋装
2. 2K-5K 装箱 (按照实际需求)

GENERAL TOLERANCE (UNLESS SPECIFIED)	DWN		
	CHK		
≤10 ±0.1	APVD		TITLE
<10°≤20 ±0.2	UNIT	REV	PART NO
<20°≤50 ±0.5	MM	A	
Angle ±3°	SIZE	SHEET	DRAWING NO
	A4	1 OF 1	

棒状天线

2.4G胶棒天线

P1951