
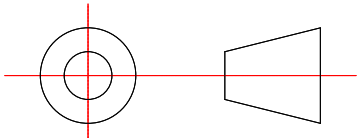


技术特性

- 温度范围: Temp.range -65~+165° C (PE Cable -40~+85° C)
- 振动: Vibration MIL-STD-202,Method 213
- 特性阻抗: Impedance 50 Ω
- 频率范围: Frequency Range DC~0-6GHz
- 工作电压: Working Voltage 335V max (有效值)
- 耐压: Withstand Voltage 1000V rms (海平面最小值)
- 接触电阻: Contact resistance
- 内导体之间: Center Contact $\leq 3 \text{ m}\Omega$
- 外导体之间: Outer Contact $\leq 2 \text{ m}\Omega$
- 绝缘电阻: Insulation resistance $\geq 5000 \text{ M}\Omega$
- 插入损耗: Insertion loss $\leq 0.15 \text{ dB}/6\text{GHz}$

GENERAL TOLERANCE (UNLESS SPECIFIED)	DWN		
	CHK		
$\leq 10 \pm 0.1$ $<10^{\circ} \leq 20 \pm 0.2$ $<20^{\circ} \leq 50 \pm 0.5$ Angle $\pm 3^{\circ}$	APVD		TITLE 射频座
 THIRD ANGLE	UNIT MM	REV A	PART NO MCX-KWE
	SIZE A4	SHEET 1 OF 1	DRAWING NO STA-10402