

SPECIFICATIONS

Mechanical

Plug Mating Force: 3.00kg (6.61Lb) max.
Plug Unmating Force: 0.40~3.00kg (0.88~6.61Lb)
Contact Retention Force: 0.50kg (1.10Lb) min.
Durability: 1500 Cycles

Electrical


Current Rating: 1.00A
Contact Resistance: 50mΩ max.(Initial)
 100 mΩ max.(After life test).
Dielectric Withstanding Voltage: 500V AC/1min min.

Physical


Housing: Thermoplastic, UL 94V-0 rated
Contact: Copper alloy
Plating: See "ORDERING INFORMATION"
Operating Temperature: -25 to +85
Recommended Thickness of PCB: 1.60[.063]

Audio Jack Connector

JA Series
Stack HD Jack, R/A, T/H
Type Ø3.5mm [.138"]
9 Pos.

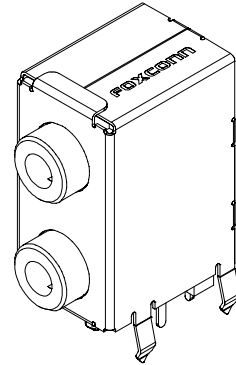

DRAWING

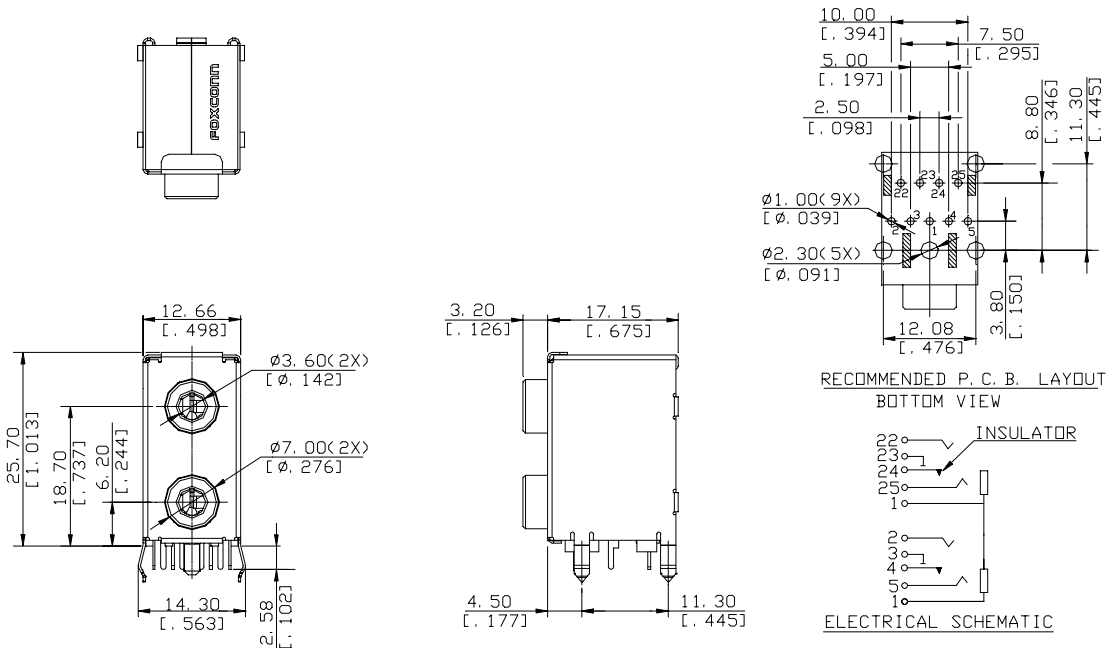

ORDERING INFORMATION

PRODUCT NO.: JA 2 3 3 3 1 - HA6Q - 4F

