



BST-300



静音超声波清洗机不锈钢超声清洗机1.8L BEST-300

- ▶ 型号: BT-300
- ▶ 材质: 不锈钢
- ▶ 电压: 110V / 50Hz的220 / 60Hz的
- ▶ 功率: 50W
- ▶ 罐尺寸 (mm) : 150 * 137 * 100
- ▶ 外形尺寸 (mm) : 175 * 165 * 200
- ▶ 包装尺寸: 245 * 220 * 245毫米 (L / W / H)
- ▶ 毛重: 1.95KG

[Contact Now](#)

Features

大功率变频器的高级清洁效果
只需轻点水，加洗涤剂清洗
大油箱容量为专业清洁
隔离电路设计，保持水带走，增强安全性
安静，固态电路

Specification

型号	BT-300
材料	不锈钢
电压	110V / 50Hz的220 / 60Hz的
动力	50W
工作频率	40KHz的
容积	1.8L
水箱尺寸 (mm)	150 * 137 * 100
外形尺寸 (mm)	175 * 165 * 200

Application

- *电子行业精密部件
- *医院和医疗设施: 手术工具, 喷油器等。
- *牙科诊所和实验室: 假牙, 牙科工具ECT
- *工业制造: 零配件, PCB, 螺丝ECT
- *珠宝首饰行业的复杂的零件: 戒指, 项链, 耳钉等。
- *在日常生活中的个人物品: 眼镜, 隐形眼镜, 梳子, 牙刷, 刀叉。


Description



Name:	Ultrasonic cleaner	Model:	BST-300
Power:	50W	Volume:	1.8L
Voltage:	110V/220V 50Hz	Frequency:	40KHz
Tank size:	150*137*100mm	Packing size:	245*220*245mm
Weight:	1.9Kg	work time:	12h
Featuer1:	Transducer with high power and strong effect.		
Featuer2:	The volume is large enough for professional cleaning.		
Featuer3:	With a forced cooling device, which can work very long.		
Featuer4:	Safety circuit design, PCBA curing treatment.		
Featuer5:	Switzerland introduced the advanced technology of elaborate design, using CPU control.		
Featuer6:	Systemic use stainless steel to create, the appearance is very beautiful, high work efficiency, stable performance.		
Featuer7:	Widely used in optical and clock parts, micro bearing, jewelry, medical equipment, electronic PCB board high requirements etc.		

Size



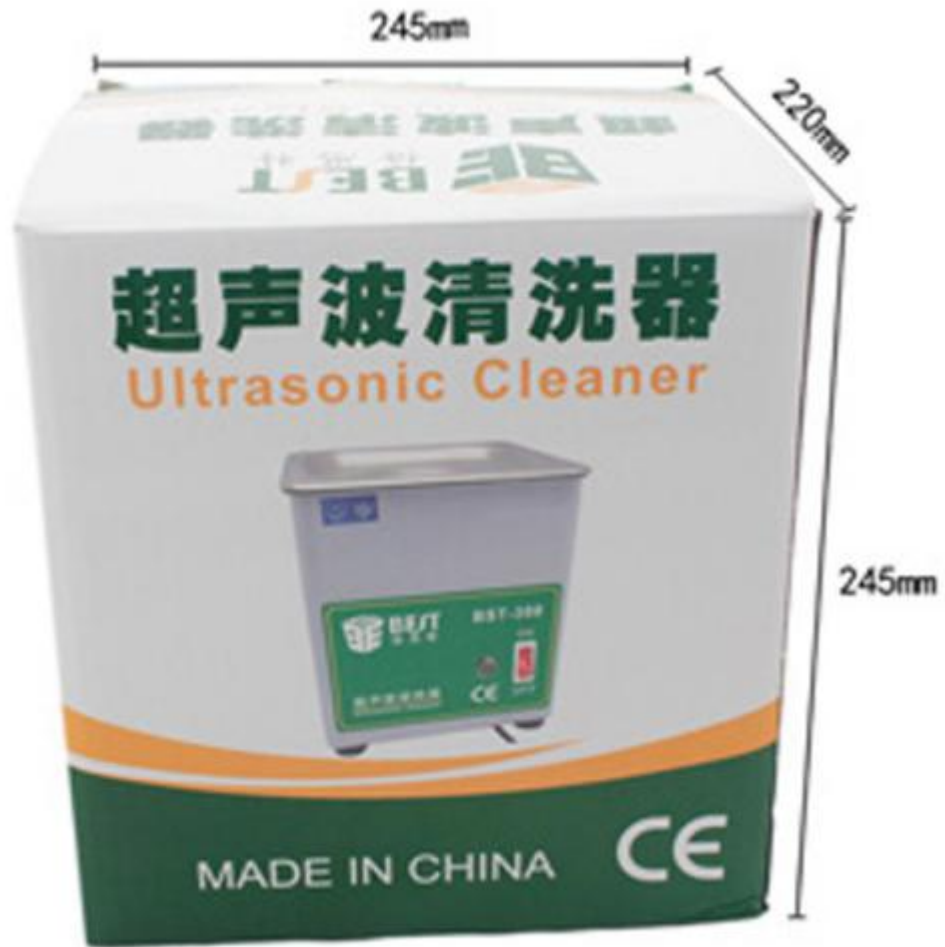

Display

Front



Side



Back



CAUTION

- Do not operate the machine without liquid in the tank.
- Maintain min. level of liquid to be 2/3 of the tank volume at all time.
- Do not use strong acid/alkaline liquid.
- Please use basket to avoid materials into contact directly with the tank.

CE RoHS

Package



Usage

