





- Flyback Transformer**
- RoHS Compliance Product**
- Surface Mount Device Providing Compact Footprint**
- Operating temperature range:-40⁰C to +125⁰C**

Electrical Specifications @ 25°C

Part Number	Turns Ratio		OCL @20KHz 0.1V	LL @100KHz 0.1V	DCR		Hi-Pot (VAC 5mA 1Sec)
	3-2: 5-7	3-2:6-8	3-2	3-2 (5+6+7+8short)	3-2	5,6-7,8	PRI. TO SEC.
TSA048	2.5:1±2%	2.5:1±2%	40uH ±10%	0.7uH max	98mΩ MAX.	26mΩ MAX.	1500

Mechanical

Schematic

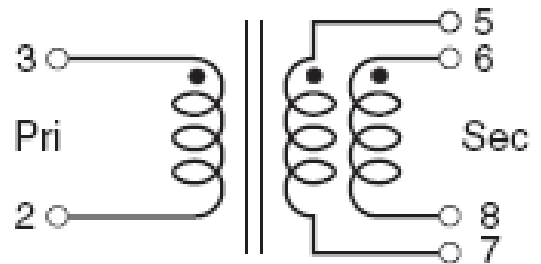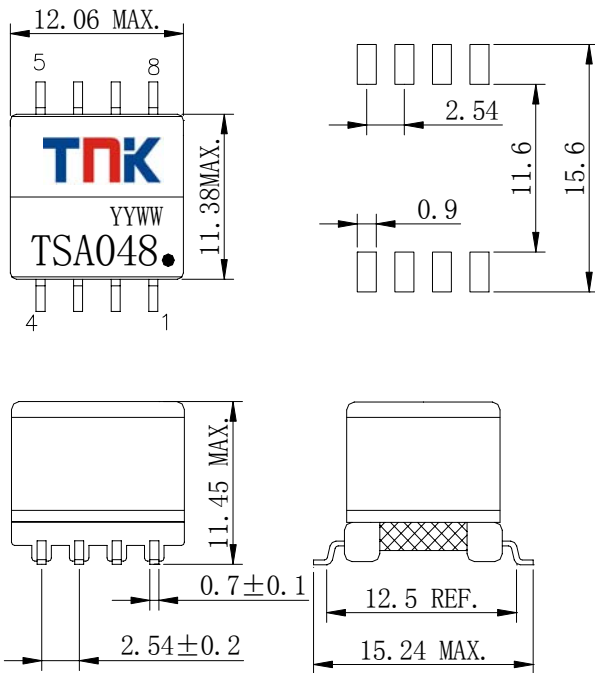

Secondary windings to be connected in parallel on PC board

NOTE:

- 1、Dimensions:mm;
- 2、 Unless otherwise specified,tolerances:±0.25(mm);