

ELU

**FEATURES**

- ※ Compact sized
- ※ Sharp detection feeling


**APPLICATION**

- ※ Consumer electronics
- ※ Safety control device
- ※ Heat energy regulator


**SPECIFICATION**

Contact Rating	100 $\mu$ A, 3V DC min. 1mA, 5V DC max.
Contact Resistance	3 $\Omega$ max.
Insulation Resistance	100M $\Omega$ min. 100V DC
Dielectric Strength	100V AC/1 minute
Operating Force	35gf max.
Travel	2.50mm
Operating Life	50,000 cycles
Operating Temp.	-40°C ~ +85°C
Storage Temp.	-40°C ~ +85°C

**HOW TO ORDER**

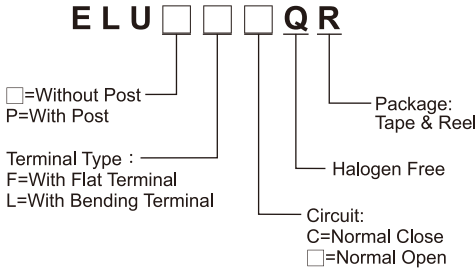

**CIRCUIT**

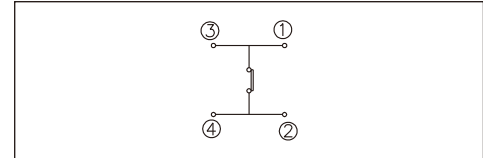

**PACKAGE**

<Tape & Reel>  
2000 pcs

**ELU**

