

ZCAT2035-0930A-BK



| | |
|------|-----------|
| 用途 | 一般等级 |
| 产品型 | 电缆固定型 |
| 适用电缆 | Φ6mm~Φ9mm |
| 系列 | ZCAT |
| 状态 | 量产体制 |



尺寸

| | |
|---|-----------------|
| A | 35.00mm ±1.00mm |
| B | 28.00mm ±1.00mm |
| C | 9.00mm ±1.00mm |
| D | 19.50mm ±1.00mm |
| E | 17.40mm ±1.00mm |

电气特性

| | |
|---------------|------------------|
| 阻抗 (Min.) / Ω | 50 (10~100MHz) |
| | 100 (100~500MHz) |


其他

| | |
|------------|--------------|
| 使用温度范围 | -40 to 85° C |
| AEC-Q200 | No |
| Case Color | 黑 |
| 包装个数 | 480pcs |
| 重量 | 21.2g |

ZCAT2035-0930A-BK



特性图表 (这是参考数据，并不保证产品的特性。)

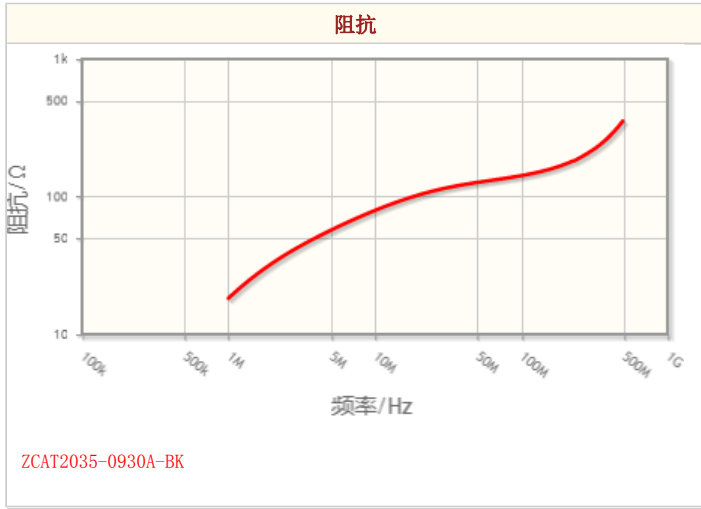


! Images are for reference only and show exemplary products.
! This PDF document was created based on the data listed on the TDK Corporation website.
! All specifications are subject to change without notice.

ZCAT2035-0930A-BK



Associated Images

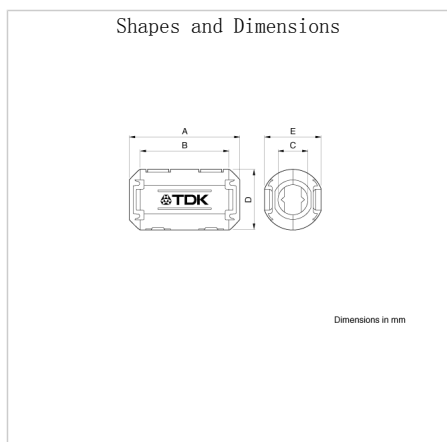

! Images are for reference only and show exemplary products.
! This PDF document was created based on the data listed on the TDK Corporation website.
! All specifications are subject to change without notice.