

环保物料

TEL:0769-82001899

SPecifications




Current Rating: 2AMP

Contact: Phosphor bronze

Plating: Gold or tin over nickel

Operating Temperature: -40°C to +105°C

Insulator body: Glass filled thermoplastic Polyester
self-extinguishing, rated UL94-V0

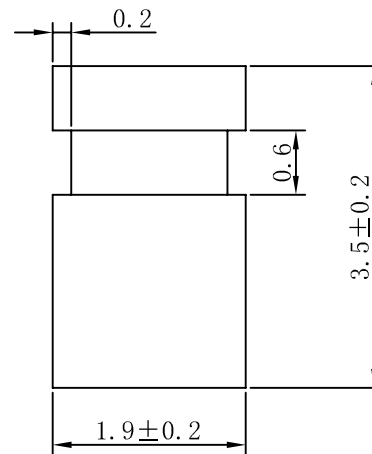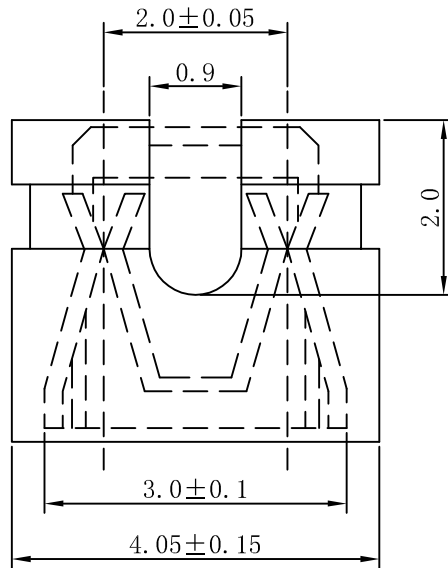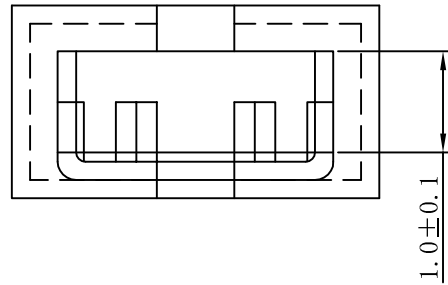

				TOLERANCE UNLESS OTHERWISE		DRAWN	CK tan	XFCN兴飞连接器有限公司 CONNECTORS XFCN CONNECTORS CO., LTD.		SHEET	1/1
				X.	±0.30	X°	±5°			CHKD	DATE
				.X	±0.20	.X°	±2°	APPD	PRODUCT NAME	JUMP 2.0 塑高3.5 常開	
				.XX	±0.08	.XX°	±1°	VIEW	PART. NO.	SCALE	1:1
				.XXX	±0.03	.XXX°	±0.5°			DWG. NO.	009
A0	MODIFICATION		DRAW	DATE				F200D-02-PT-B			
VER											