


# 涤纶电容

4.7nF (472) 100V


标称容量：4.7nF

容量允许偏差：±5%

额定电压：100VDC

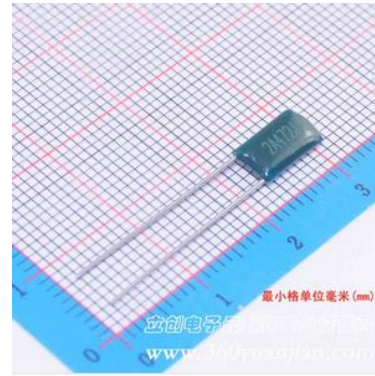

## 尺寸大小

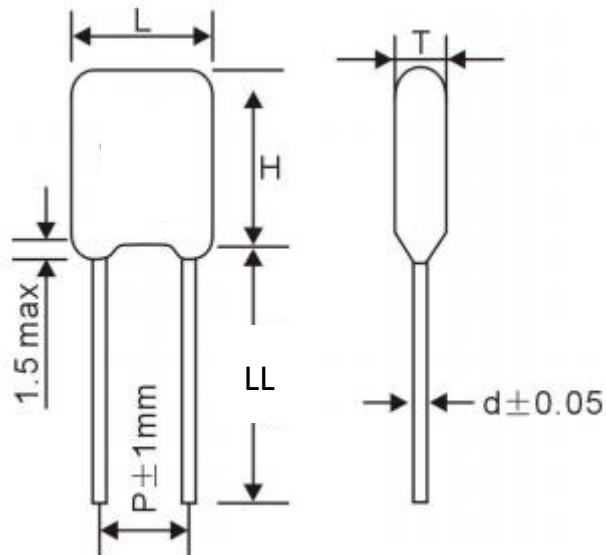

L:5.0±0.5mm    H:9.0±1mm    P: 3.5mm    LL:21.0±1mm    d: 0.6±0.06mm