


涤纶电容

47nF (473) 100V


标称容量：47nF

容量允许偏差：±5%

额定电压：100VDC

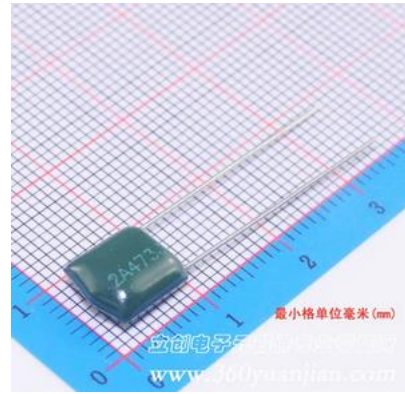

尺寸大小

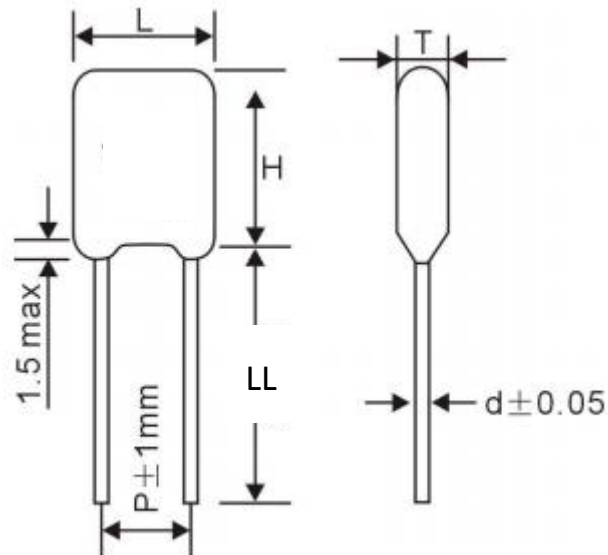

L:5.0±0.5mm

H:9.0±1mm

P: 3.5mm

LL:25.0±1mm

d: 0.6±0.06mm