

DMSH-50S (F) 白铆锁鱼叉 ROHS



D-SUB CONNECTOR

DMS Series



Specifications

Current rating	: 3A
Withstanding voltage	: 1000V AC RMS
Insulation resistance	: 3000M Ω Min
Contact resistance	: 15m Ω Max
Temperature range	: -55 $^{\circ}$ C ~ +105 $^{\circ}$ C

> DMS-50S <


Material:

Insulator : P.B.T Glass Fibre
UL94V-0

Color : White, Blue, Black.

Contact : Brass or Phosphor Bronze

Plating: Gold Flash in Contact Area

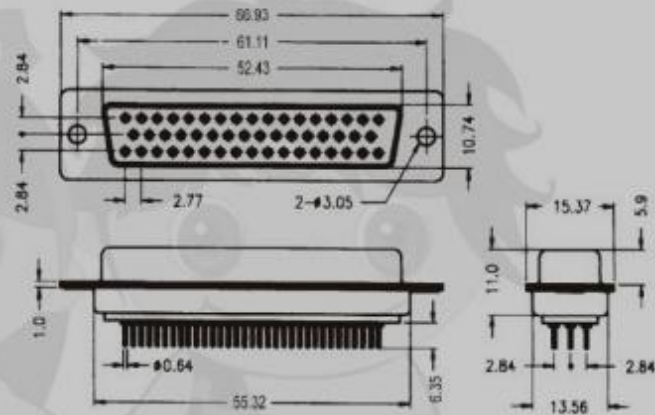

Dimension:mm